

**New**

# Motor gearboxes 12 and 24 Vdc

Torque from 0.1 to 2 Nm

**BUH77**

- Gearbox type : spur gear
- Bearing : bronze
- Max axial load : 10N
- Max radial load : 30N at 5mm from flange
- Angular backlash : 0.05 to 0.6mm
- Working temp : from -10° to 70°C
- Weight : 250g

## Application


- Drives, ideal for Start/Stop applications or reverse applications

## Advantages

- Compact size
- High torque

## Accessories

- Servoamplifier: **NANODC-1A-30/3** (speed controller)
- Power supply **ALIDR30-12, ALIDR30-24**

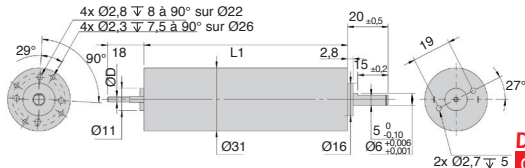**NEW!**

## DISCOUNTS

Qty	1+	6+	10+
Disc Price		-7%	on request

Part number	Reduction	N° of stages	ØD	L1 (mm)	No-load speed (rpm)	Speed under load (rpm)	Nominal torque (Nm)	Nominal current (A)	Price each
<b>12V DC Version</b>									
BUH77-12-004	3,4	1	3	100,5	1215	900	0,10	1,4	174,80 €
BUH77-12-012	11,6	2	3	106,6	355	260	0,30	1,4	174,80 €
BUH77-12-022	21,4	2	3	106,6	190	140	0,55	1,4	174,80 €
BUH77-12-040	39,7	2	3	106,6	105	75	1,00	1,4	183,33 €
BUH77-12-135	135	3	2,5	88,5	33	23	1,80	0,85	183,33 €
BUH77-12-250	250	3	2,5	88,5	18	14	2,00	0,85	183,33 €
<b>24V DC Version</b>									
BUH77-24-004	3,4	1	3	100,5	1215	900	0,10	0,7	174,80 €
BUH77-24-012	11,6	2	3	106,6	355	260	0,30	0,7	174,80 €
BUH77-24-022	21,4	2	3	106,6	190	140	0,55	0,7	185,46 €
BUH77-24-040	39,7	2	3	106,6	105	75	1,00	0,7	185,46 €
BUH77-24-135	135	3	2,5	88,5	33	23	1,80	0,425	185,46 €
BUH77-24-250	250	3	2,5	88,5	18	14	2,00	0,275	185,46 €

Dimensions in mm

## Altri prodotti...



RESC

Ruote con supporto di livellamento, Ruote con supporto di livellamento



ZG4

Ingranaggio dritto in plastica, Plastica lavorata (delrin)



PTA150

Piede snodato con base stampata Ø150, 40000N



AT5M AT10M

Cinghia aperta al metro tipo AT, AT5 Poliuretano armatura in acciaio



MAX26

Motoriduttore DC 12V e 24V DC, da 0,075 a 0,6Nm



DCG

Ventosa, nitrile



CLA

Maniglia a ripresa Hygienic Usit®, Inox



DOM120

Kit di raccordo, Kit di raccordo XZ




UCP\_SS

Cuscinetto ritto tutto inox, Inox



CHA35

Cerniera ad avvitare, Cerniera

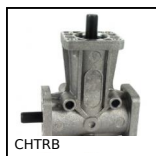

CHTRB

Riduttore a rinvio angolare a L o a T, fino a 53,1 Nm



PTAF80-PAMF80

Piede fissabile con base lamiera Ø80, Ø 80

## Prodotti correlati



NANO

Variatore di velocità 3A, 3 A



ALIDR30

Alimentazione, 1,5 A and 2 A