

Adjustable screw stop


Steel

BVR


- Allows to easily create a stop that is adjustable over a 50mm range
- Material:
Burnished treated steel

Application

- Can be adjusted over the full range
- Final position is locked using a counter-nut.

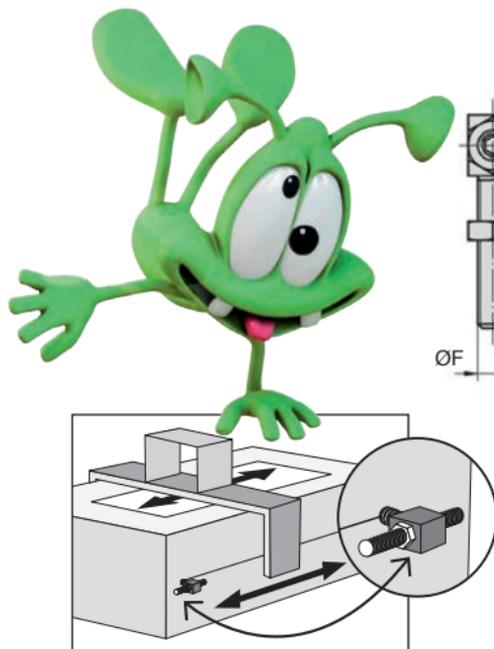

Travel stop

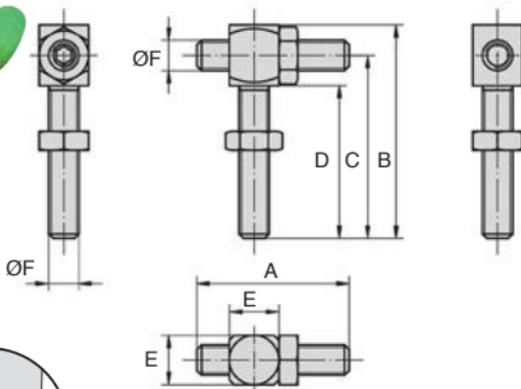

DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	D	E	ØF	Price each 1 to 5
BVR6-30-30	30	44	37	30	10	M6	19,88 €
BVR8-40-40	40	56	48	40	13	M8	25,81 €
BVR10-50-50	50	70	60	50	17	M10	30,28 €
BVR12-60-60	60	84	72	60	19	M12	39,24 €
BVR16-80-80	80	112	96	80	24	M16	60,02 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

199

Altri prodotti...



BOX-TOR-INCH

Valigetta di guarnizioni toriche in nitrile, For fasteners and fitting



PSG25

Ingranaggio dritto di precisione, Inox 303




PRF JL2

Panel accessories, Guarnizione - Ø 2mm



SH1

Ingranaggio elicoidale ad assi paralleli, Plastica lavorata (delrin)

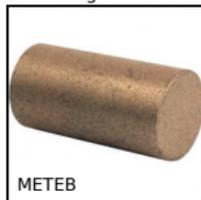

METEB

Barre autolubrificanti, Bronzo BP25



RNAST

Rotelle, Senza anello interno



BPTR

Tappo per tubo tondo, Standard



BPL

Sfera portante con flangia, Leggero



LBE

Manicotto a sfere Mini, Miniatura



TBD

Tavola di posizionamento a



DOMI50

Accessori di collegamento, Leva di



CLLCLLP

Perno serie lunga, Acciaio - serie lunga

Prodotti correlati