

# Adjustable screw stop


Steel

BVR


- Allows to easily create a stop that is adjustable over a 50mm range
- Material:  
Burnished treated steel

## Application

- Can be adjusted over the full range
- Final position is locked using a counter-nut.

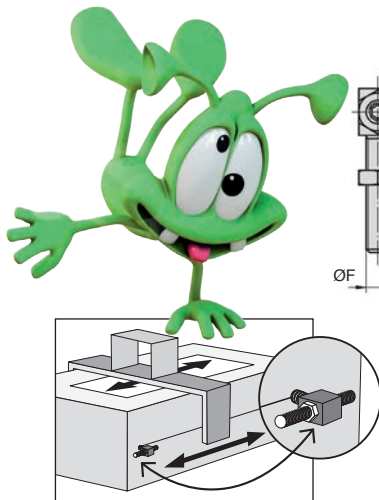

Travel stop

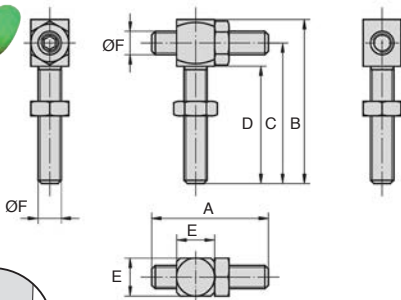

## DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	D	E	ØF	Price each 1 to 5
BVR6-30-30	30	44	37	30	10	M6	19,88 €
BVR8-40-40	40	56	48	40	13	M8	25,81 €
BVR10-50-50	50	70	60	50	17	M10	30,28 €
BVR12-60-60	60	84	72	60	19	M12	39,24 €
BVR16-80-80	80	112	96	80	24	M16	60,02 €

Dimensions in mm

**0 825 88 6000**  
Service 0,15 € / min  
+ prix appel

Fax

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019


199

## Altri prodotti...



COA-COG

Staffa di montaggio per molla a gas, Staffa di montaggio piana per s...

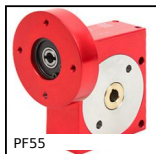

PF55

Riduttore a ruota e vite senza fine, fino a 57 Nm



BOX-CSss

Fascette di serraggio, Valigetta di fascette inox



SER

Accessori per porte, Fermaporte a calamita



HRV

Sistema di guida su binario a V Simple Select®, Binario con carrello



HRV

Sistema di guida su binario a V Simple Select®, Binario con carrello



DKN

Giunto a soffietto Gerwah®, da 0.4 a 10Nm



MSP23

Inserito con piastrina a incollare Masterplate®, Cilindrico Ø23 con...



S\_ZZ

Cuscinetto radiale a sfere, Inox




CHT

Motore AC asincrono trifase, 0.12 a 0.22kW



PLM-SC

Magnete piatto con foro svasato, Con foro

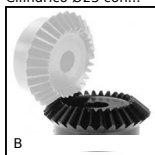

B

Ingranaggio conico - Acciaio 60C40, 1:1

**Prodotti correlati**