


- Ideal for moving large or heavy loads
- Completely smooth surface
- With double hinge
- Materials:
  - Plates: polished cold-laminated stainless steel (30HRC min.)
  - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)



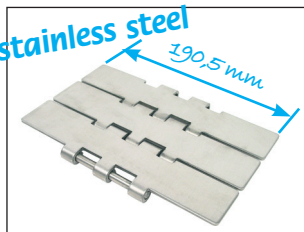


### Advantages

  - Large width
- High carrying capacity

### Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL805**

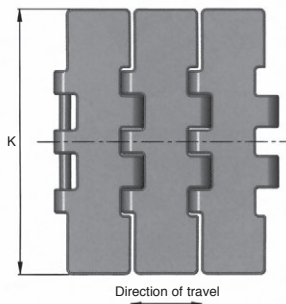

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request


Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP805-190/SS	190,5	3048	19000	5,8	252,74 €

Dimensions in mm

## Altri prodotti...



DOMI80  
Accessori di collegamento, Piatto girevole

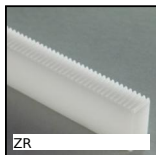


ZR  
Cremagliera in plastica, Delrin




PSG125HC  
Ingran. dritto di precisione trattato skiving, Acciaio 20NCD2 cement...



SSG\_304L  
Ingranaggio dritto Inox, Inox 304L

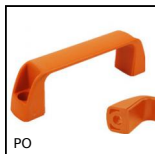

PO  
Maniglia a ponte - Multi-settore, Foro liscio

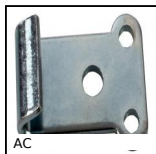

AC  
Pastrina di riscontro, 15mm



BRI  
Accessori per pannello, Blocco di fissaggio



AT5M AT10M  
Cinghia aperta al metro tipo AT, AT10 Poliuretano armatura in acciaio



ACM\_AZ  
Aggancio per tirante chiusura in gomma, Aggancio



TCC  
Tenditore, Acciaio



RFK28B  
Riduttore ipoide inox, fino a 130 Nm



PHG05  
Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2 cementato t...


## Prodotti correlati



PT821  
Pignone di trazione, Serie 821 e 805



PR821  
Ruota di rinvio, Serie 821 e 805

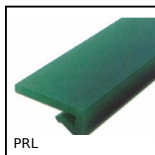

PRL  
Profilo supporto per catena, Profilo ad L ad incastro