

- Ideal for moving large or heavy loads
- Completely smooth surface
- With double hinge
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)






Advantages

- Large width
- High carrying capacity

Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL805**

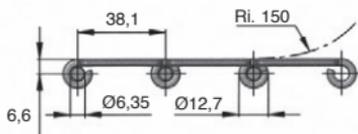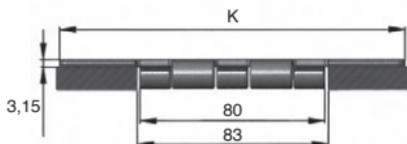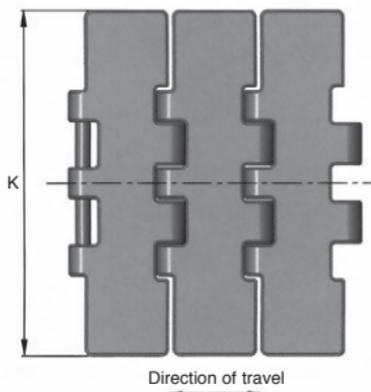

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP805-190/SS	190,5	3048	19000	5,8	252,74 €

Dimensions in mm

Altri prodotti...



WINGbr
Vite ad alette DIN316,
Ottone DIN 316



NKIB
Cuscinetto combinato
con anello interno,
Carico assiale
bidirezionale



PRF-SCREEN-4
Screen support,
Support with 4 axes of
rotation



RAS
Snodo angolare a 90°
DIN71802, Inox



BCM_CC
Spazzola cilindrica
modulare, Filo di crine di
cavallo



PCS50SS
Pignone a catena -
Inox, 12.7mm (DIN
08B-1)



GALRUB
Rullo per
trasportatore, Caucciù



YG1
Ingranaggio dritto
PRESTAZIONE, Acciaio
35NCD6



ZBconique
Ingranaggio conico in
plastica, 1:1



RHTplss
Ruota alte
temperature, fino a
500°C



WS20
Binario Drylin® W,
Binario



CHAC4040NP
Cerniera, Quadrata
con rivetto senza fori


Prodotti correlati



PT821
Pignone di trazione,
Serie 821 e 805



PR821
Ruota di rinvio, Serie
821 e 805

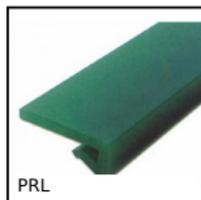

PRL
Profilo supporto per
catena, Profilo ad L ad
incastro