


- Ideal for moving large or heavy loads
- Completely smooth surface
- With double hinge
- Materials:
  - Plates: polished cold-laminated stainless steel (30HRC min.)
  - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)
- Length 3048mm (80 plates)



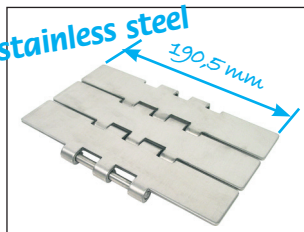


### Advantages

  - Large width
- High carrying capacity

### Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL805**

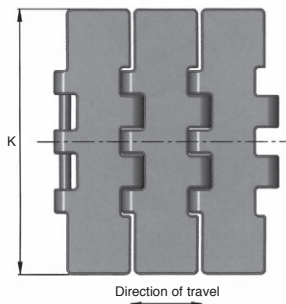

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty.  | 1+   | 5+  | 10+        |
| Disc. | List | -5% | On request |

| Part number   | Width K (mm) | Length (mm) | Breaking load (N) | Weight (kg/m) | Price each 1 to 4 |
|---------------|--------------|-------------|-------------------|---------------|-------------------|
| CAP805-190/SS | 190,5        | 3048        | 19000             | 5,8           | 252,74 €          |

Dimensions in mm

## Altri prodotti...



RFK38C  
Riduttore ipoidale inox,  
fino a 200 Nm




SHSS  
Vite a spalla inox 416,  
Inox 416 pretrattato



AK  
Giunto a soffietto  
Gerwah®, da 36 a  
800Nm



RT25  
Calettatore di  
bloccaggio, Coppia  
media/elevata

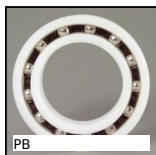

PB  
Cuscinetto in plastica,  
Plastica - materiale  
sfere : inox



DOMI30  
Slitta di regolazione  
Domino 30, Slitta  
DOMILINE 30 con  
contatore e ...



GAE  
Chiusura a leva con  
serratura, senza  
serratura



CLSCLP\_SS  
Forcella e perno serie  
corta, Corta inox



CHM63  
Riduttore a ruota e  
vite senza fine, fino a  
196 Nm



COA-COG  
Staffa di montaggio  
per molla a gas,  
Staffa di montaggio



ATZY  
Antivibrante elastico  
sgolato, Acciaio



ASL  
Anello di  
sollevamento, a 45° a  
saldare


## Prodotti correlati



PT821  
Pignone di trazione,  
Serie 821 e 805



PR821  
Ruota di rinvio, Serie  
821 e 805

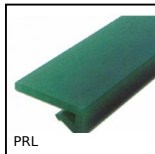

PRL  
Profilo supporto per  
catena, Profilo ad L ad  
incastro