


- Main applications are in bottling plants and for moving hard products
- Smooth surface with no backlash
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)


 
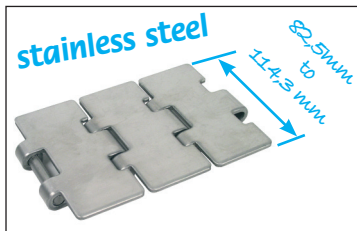


Advantages

- Wide field of applications

Associated products

- Drive sprocket **PT820**
- Idler sprocket **PR820**
- Idler **DBL820**

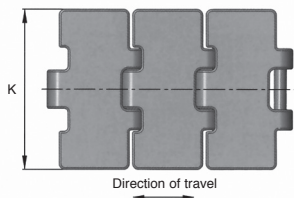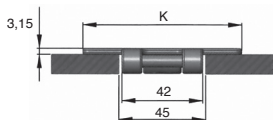


DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP815-82/SS	82,5	3048	10400	2,65	111,27 €
CAP815-114/SS	114,3	3048	10400	3,40	161,87 €

Dimensions in mm

Altri prodotti...

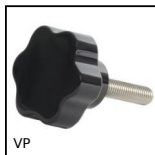

VP

Volantino a 6 lobi,
Duroplast - Acciaio



PRF-SCREEN-1

Screen support, Basic
support



CHAR7520

Cerniera a molla,
avvitabile



SHN

Dado esagonale -
DIN934, Acciaio (Class
6J8)



MSP3815

Inserto con piastrina a
incollare
Masterplate®,
rettangolare con pe...



PAL

Dado di sicurezza, Per
bloccaggio assiale



CMM

Testa a snodo
maschio DIN
ISO12240-4, Acciaio /
bronzo



SA_SAKH

Supporto per
manicotto, Chiuso -
carico leggero




APB_T

Perno di fissaggio per
morsetti, Maschiato



PLN

Distanziatore
cilindrico,

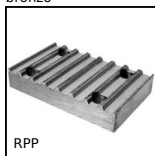

RPP

Piastra di giunzione
per cinghia RPP, RPP5



GCL

Guida lineare a sfere
Eco, economica

Prodotti correlati



PR820

Ruota di rinvio, Serie
820 e 815



DBL820

Rotella per catena,
Serie 820 e 815



CAP820

Catena a tapparella
dritta, Stretta serie
820



GALRUB

Rullo per
trasportatore, Caucciù