


- Main applications are in bottling plants and for moving hard products
- Smooth surface with no backlash
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)


 
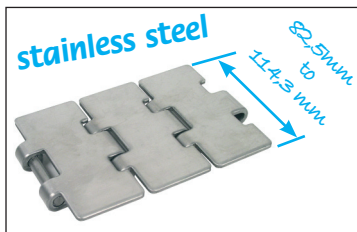


Advantages

- Wide field of applications

Associated products

- Drive sprocket **PT820**
- Idler sprocket **PR820**
- Idler **DBL820**

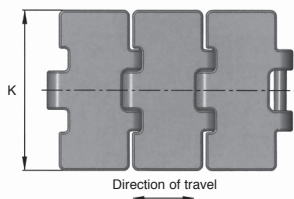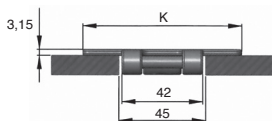


DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP815-82/SS	82,5	3048	10400	2,65	111,27 €
CAP815-114/SS	114,3	3048	10400	3,40	161,87 €

Dimensions in mm

Altri prodotti...

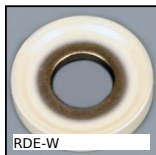

RDE-W

Rondella di tenuta Hygienic Usit®, Inox - EPDM bianco



DB

Ingranaggio conico in acciaio, 2:1



GPB

Impugnatura sferica, Con inserto ottone



SCH

Attrezzo di bloccaggio a tirante, A tirante orizzontale - acciaio



SH0

Ingranaggio elicoidale ad assi paralleli, Plastica lavorata (delrin)



PM4

Vite senza fine, Acciaio temprato



SHA_PTR

Volantino pieno, Poliammide



CHAL3

Cerniera piana, Acciaio



NSB

Supporto standard per manicotto chiuso a sfere, Chiuso - Lungo



M0

Ruota per vite senza fine, Bronzo



SBF

Sealed flange bearing unit for Food Industry, cover



VEL

Rotolo a strappo fermacavi, cavi elettrici e pneumatici

Prodotti correlati



PR820

Ruota di rinvio, Serie 820 e 815



DBL820

Rotella per catena, Serie 820 e 815



CAP820

Catena a tapparella dritta, Stretta serie 820



GALRUB

Rullo per trasportatore, Caucciù