

- Main applications are in bottling plants and for moving hard products
- Smooth surface with no backlash
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)






Advantages

- Wide field of applications

Associated products

- Drive sprocket **PT820**
- Idler sprocket **PR820**
- Idler **DBL820**

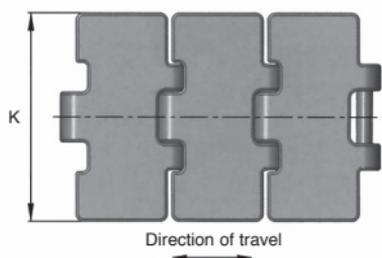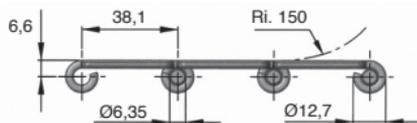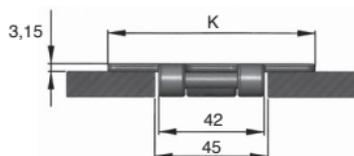


DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP815-82/SS	82,5	3048	10400	2,65	111,27 €
CAP815-114/SS	114,3	3048	10400	3,40	161,87 €

Dimensions in mm

Altri prodotti...

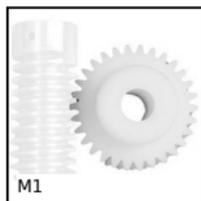

M1

Ruota per vite senza fine, Plastica lavorata (delrin)



BOXbeta

Box kit di spine beta, Box kit - beta



PTAF100-PAMF100

Piede fissabile con base lamiera Ø100, Ø 100



SERB

Serratura a camme, Serratura a camme



D-PAR_SS

Piedino antivibrante parabolico, inox



SLBE

Pistoncino a molla, Anello distanziatore per pistoncino a molla SLB



PM2

Vite senza fine, Acciaio non temprato



DOM120

Accessori di collegamento, Piatto girevole



DBL820

Rotella per catena, Serie 820 e 815



ADL

Anello di sollevamento,



DCG

Ventosa, silicone



EV

Terminale rapido inox per cavi,

Prodotti correlati



PR820

Ruota di rinvio, Serie 820 e 815



DBL820

Rotella per catena, Serie 820 e 815



CAP820

Catena a tapparella dritta, Stretta serie 820



GALRUB

Rullo per trasportatore, Caucciù