


- Main applications are in bottling plants and for moving hard products
- Smooth surface with no backlash
- Materials:
 - Plates: polished cold-laminated stainless steel (30HRC min.)
 - Pin: special stainless steel (41-44HRC)
- Operating temp.: -40°C to +260°C (+120°C in humid environments)


 
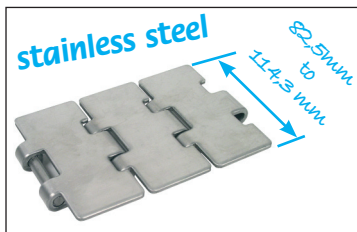


Advantages

- Wide field of applications

Associated products

- Drive sprocket **PT820**
- Idler sprocket **PR820**
- Idler **DBL820**

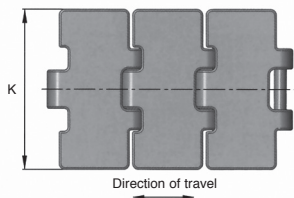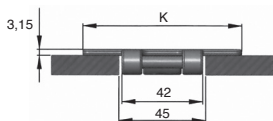

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP815-82/SS	82,5	3048	10400	2,65	111,27 €
CAP815-114/SS	114,3	3048	10400	3,40	161,87 €

Dimensions in mm

Altri prodotti...



GET-AL
Giunto elastico
alluminio serie eco.,
Alluminio




PPC55
Piastrina con anello,
Inox



Q6
Cuscinetto radiale a
sfere, Acciaio




RHTplss
Ruota alte
temperature, fino a
200kg

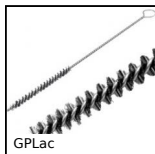

GPLac
Scovolo, acciaio



CMM_SS
Testa a snodo
maschio DIN
ISO12240-4, Inox /
bronzo - Série

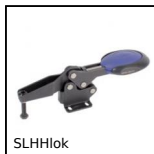


SLHHlok
Bloccaggio a leva, A
leva orizzontale / base
orizzontale



AK
Giunto a soffietto
Gerwah®, da 36 a
800Nm



SSDB
Ingranaggio conico
inox, 2:1

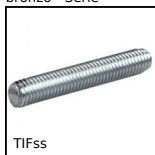

TIF55
Tirante tutto filetto -
DIN976A, Inox



KH
Manicotto a sfere,
Leggera



H0
Ingranaggio elicoidale
ad assi incrociati a
90°, Acciaio 20NCD2

Prodotti correlati



PR820
Ruota di rinvio, Serie
820 e 815



DBL820
Rotella per catena,
Serie 820 e 815



CAP820
Catena a tapparella
dritta, Stretta serie
820



GALRUB
Rullo per
trasportatore, Caucciù