

- Ideal for moving bottles and metal cans at high speeds

- Smooth surface with no backlash
- Non knurled pin


- Materials:

Plates: low friction acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C (+70°C in humid environments)

- Length 3048mm (80 plates)


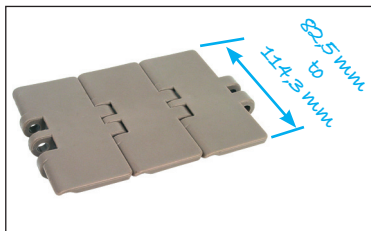


Advantages


- In most applications no lubrication is necessary

Associated products

  - Drive sprocket **PT820**
- Idler sprocket **PR820**
- Idler **DBL820**



Direction of travel →

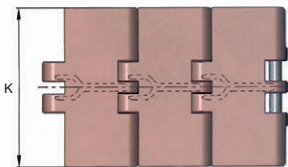

DISCOUNTS

| Qty. | 1+ | 5+ | 10+ |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number | Width K (mm) | Length (mm) | Breaking load (N) | Weight (kg/m) | Price each 1 to 4 |
|-------------|--------------|-------------|-------------------|---------------|-------------------|
| CAP820-82 | 82,5 | 3048 | 3200 | 0,83 | 80,63 € |
| CAP820-114 | 114,3 | 3048 | 3200 | 1,03 | 102,69 € |

Dimensions in mm

Altri prodotti...



PLM-205C

Magnete cilindrico di fermo filettato,
Magnete di fermo maschiato




AT10-BAR

Barra dentata, AT10



BLHB30

Rinvio angolare ad albero cavo, fino a 4.47 Nm

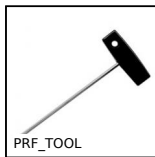

PRF_TOOL

Attrezzi, Chiave di montaggio



DER63

Motore inox AC asincrono 0,18kW, 0.18kW



SSDB

Ingranaggio conico inox, 2:1



GDR880

Guida dritta, Serie 880 e 881



CSS

Snodo sferico, acciaio/acciaio autolubrificante



CLA

Maniglia a ripresa Hygienic Usit®, Inox



H02SS

Giunto cardanico semplice ad aghi -



UCF_PBT

Cuscinetto a flangia quadrata polimero



WW10

Guida Drylin® W, Carrello

Prodotti correlati



PT820

Pignone di trazione, Serie 820 e 815



PR820

Ruota di rinvio, Serie 820 e 815



CAP815

Catena a tapparella dritta, Stretta serie 815



DBL820

Rotella per catena, Serie 820 e 815