


- Ideal for moving large or heavy loads
- Completely smooth surfaces
- With double hinge
- Materials:
  - Plates: low friction acetal
  - Pin: stainless steel 304
- Operating temp.: -40°C to +85°C (+70°C in humid environments)
- Length 3048mm (80 plates)

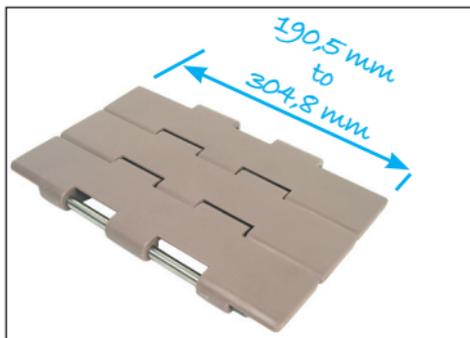




### Advantages

 - Large width
- High carrying capacity

### Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL821**

Direction of travel

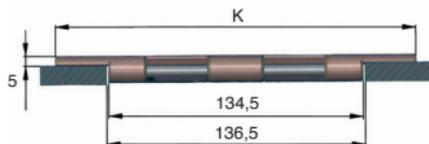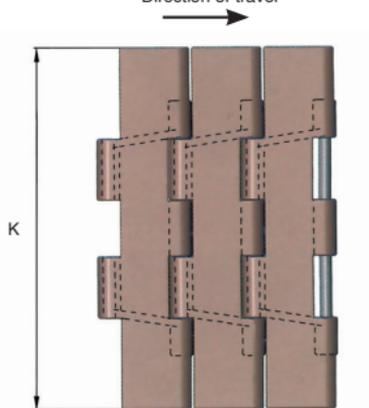

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP821-190	190,5	3048	6500	2,50	268,68 €
CAP821-254	254,0	3048	6500	2,95	283,64 €
CAP821-304	304,8	3048	6500	3,25	312,37 €

Dimensions in mm

## Altri prodotti...



TIF

Asta filettata -  
DIN975, Inox A2



WJUM10

Pattino Drylin® W,  
Pattino



G0

Ingranaggio dritto  
acciaio, Acciaio  
20NCD2



YG2

Ingranaggio dritto  
PRESTAZIONE, Acciaio  
35NCD6



SBF

Sealed flange bearing  
unit for Food Industry,  
cover



SUP

Calettatore di  
bloccaggio  
autocentrante acciaio,  
Senza ghiera



RVM14

Riduttore manuale, A  
ruota e vite senza fine



RAGFLOWsupport

Accessori per rotaia a  
rulli Floway2®, Roller  
track support



PF45

Riduttore a ruota e  
vite senza fine, fino a



GLB

Piccolo volano a 6  
alette, Tecnopolimero



BPHF

Sfera portante, Forte



NANO

Variatore di velocità  
3A, 3 A

## Prodotti correlati




PT821

Pignone di trazione,  
Serie 821 e 805



PR821

Ruota di rinvio, Serie  
821 e 805

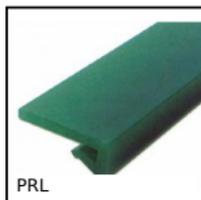

PRL

Profilo supporto per  
catena, Profilo ad L ad  
incastro