


- Ideal for moving large or heavy loads
- Completely smooth surfaces
- With double hinge
- Materials:
 - Plates: low friction acetal
 - Pin: stainless steel 304
- Operating temp.: -40°C to +85°C (+70°C in humid environments)
- Length 3048mm (80 plates)

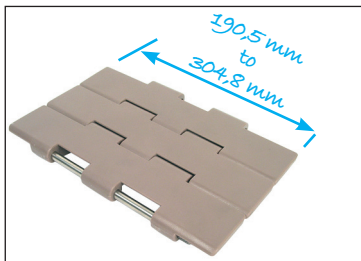

 
 

Advantages

- Large width
- High carrying capacity

Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL821**

Direction of travel

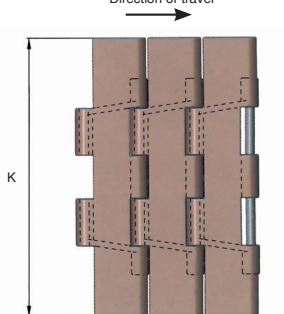

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP821-190	190,5	3048	6500	2,50	268,68 €
CAP821-254	254,0	3048	6500	2,95	283,64 €
CAP821-304	304,8	3048	6500	3,25	312,37 €

Dimensions in mm

Altri prodotti...



CNA-CNG

Staffa di montaggio per molla a gas, Staffa di montaggio a squadra p...



KB_WW

Manicotto chiuso a sfere di precisione, Economica




GSI

Molla a gas inox, Inox



CHAM5270SS

Cerniera ad avvitare inox, Marine

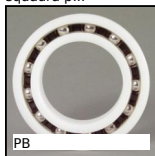

PB

Cuscinetto in plastica, Plastica - materiale sfere : inox



APB_F

Perno di fissaggio per morsetti, Filettato



PAMF100EB

Piede snodato con base stampata fissabile Ø100, Piede snodato



LVT

Mini martinetto motorizzato 1A, 1 ampere



MAX26

Motoriduttore DC 12V e 24V DC, da 0,075 a



BDMdII

Boccola magnetica per perno, Bloccaggio



CHTRB

Riduttore a rinvio angolare a L o a T,



BLH20

Rinvio angolare a L, da 0.53 a 1.77

Prodotti correlati




PT821

Pignone di trazione, Serie 821 e 805



PR821

Ruota di rinvio, Serie 821 e 805

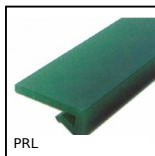

PRL

Profilo supporto per catena, Profilo ad L ad incastro