


- Ideal for moving large or heavy loads
- Completely smooth surfaces
- With double hinge
- Materials:
 - Plates: low friction acetal
 - Pin: stainless steel 304
- Operating temp.: -40°C to +85°C (+70°C in humid environments)
- Length 3048mm (80 plates)

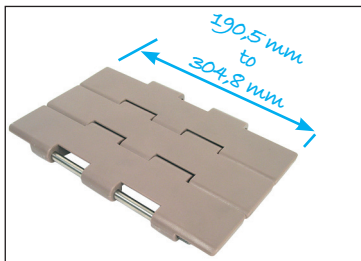

 
 

Advantages

- Large width
- High carrying capacity

Associated products

- Drive sprocket **PT821**
- Idler sprocket **PR821**
- Idler **DBL821**

Direction of travel

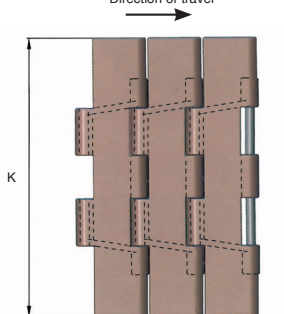

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP821-190	190,5	3048	6500	2,50	268,68 €
CAP821-254	254,0	3048	6500	2,95	283,64 €
CAP821-304	304,8	3048	6500	3,25	312,37 €

Dimensions in mm

Altri prodotti...




CLASS

Maniglia a ripresa -
femmina, Inox



PCS62SS

Pignone a catena -
Inox, 15.875mm (DIN
08B-1)

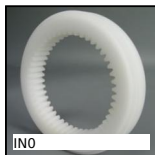

INO

Ingranaggio interno,
Plastica lavorata
(delrin)



NCT

Giunto di
collegamento, Ad
angolo fisso



M1

Coppia ruota e vite
senza fine, Acciaio
temprato



BPH

Sfera portante a
incastro cilindrico,
Forte



CHTRP

Riduttore a rinvio
angolare a L o a T,
fino a 75,7 Nm



GAL 42

Rullo per
trasportatore, Senza
cuscinetti a sfere



VTAP

Vite a testa
magnetica, Con



CHMX_CHMDX

Albero per riduttore a
ruota e vite senza fine



LVT

Mini martinetto
motorizzato 1A, 1



PRS100

Piede snodabile tutto
inox Ø100, Ø 100

Prodotti correlati




PT821

Pignone di trazione,
Serie 821 e 805



PR821

Ruota di rinvio, Serie
821 e 805

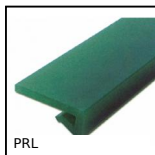

PRL

Profilo supporto per
catena, Profilo ad L ad
incastro