

Side flexing slim plate chain



CAP880T

Range 880 TAB

- **Bending radius allows chain to follow a curved path**


- **Materials:**

Plates: low friction acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- Length 3048mm (80 plates)

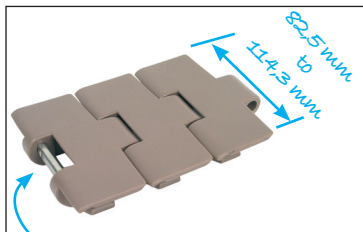

Advantages

- Special shape prevents products being carried moving or falling whilst on curves

Associated products


- Drive sprocket **PT880**

- Idler sprocket **PR880**


- Idler **DBL880**

- Straight track **GRD880T**


- Curved track **GCB880T**

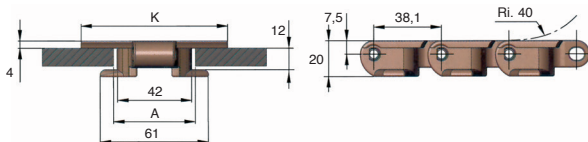

A $\left\{ \begin{array}{l} \text{Straight} - 46 \\ \text{Curved} - 44,2 \end{array} \right.$

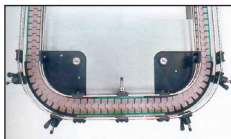

Typical application

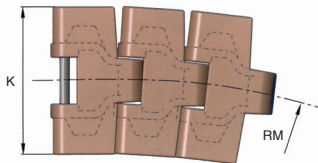

Direction of travel

DISCOUNTS

Qty.	1+	5+	10+
Disc. List	-5%	On request	

Part number	Width K (mm)	Length (mm)	Bend radius RM (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP880T-82	82,5	3048	457	5200	1,04	106,93 €
CAP880T-114	114,3	3048	532	5200	1,21	122,84 €

Dimensions in mm

Altri prodotti...




J65
Riduttore coassiale a treni paralleli, da 0.80 a 2.95 - a treni para...




PR65C
Half-articulated foot \varnothing 65, \varnothing 65



SHW
Rondella semplice ,
Inox A2

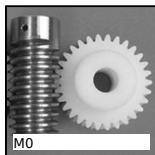

M0
Coppia ruota e vite senza fine, Plastica lavorata (delrin)

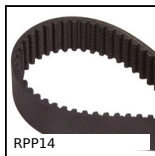

RPP14
Cinghia di trasmissione RPP, RPP14



CHMR90
Riduttore a ruota e vite senza fine, fino a 540 Nm



GE32
Chiusura a leva rigida ad anello, Standard



PLM-16A
Magnete, Con foro maschiato



BIM
Pistoncino a molla, miniatura



F7-I
Visualizzatore multifunzione, Con sensore di posizione integrato



CHMR30
Riduttore a ruota e vite senza fine, fino a 28 Nm



PSG2
Ingranaggio dritto di precisione, Acciaio 20NCD2 cementato temprato

Prodotti correlati



PR880
Ruota di rinvio, Serie 880



PT880
Pignone di trazione, Serie 880



CAP881
Catena a tapparella, Stretta serie 881



GDR880
Guida dritta, Serie 880 e 881