



Side flexing slim plate chain **stainless steel**

Range 881 TAB

CAP881Tss

- **Bending radius allows chain to follow a curved path**

- **Materials:**

Plates: polished cold-laminated stainless steel (30HRC min.)

Pin: stainless steel 302 (1400N/mm²)

- **Operating temp.:** -40°C to +260°C (+120°C in humid environments)

- **Length** 3048mm (80 plates)

Associated products


- Drive sprocket **PT881**

- Idler sprocket **PR881**


- Idler **DBL880**

- Straight track **GRD880T**


- Curved track **GCB880T**

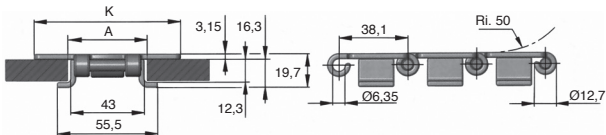

A $\left\{ \begin{array}{l} \text{Straight} - 46 \\ \text{Curved} - 44,5 \end{array} \right.$

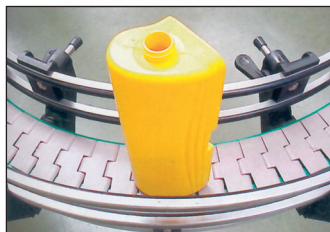

Typical application

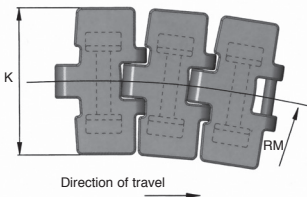

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius RM (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP881T-82/SS	82,5	3048	500	9500	2,9	205,85 €
CAP881T-114/SS	114,3	3048	500	9500	3,6	266,13 €

Dimensions in mm

Altri prodotti...



BLHB40

Rinvio angolare ad albero cavo, fino a 10.3 Nm



WS10

Guida modulabile Drylin® W, Binario



RDERSS

Tenditore, a serraggio manuale inox



UFX

Giunto elastico UNEFLEX, range



R203

Molla per stampi ISO10243, Leggero



DOMI120

Slitta di regolazione Domino 120, Slitta DOMILINE 120



SHW

Rondella semplice, Acciaio



MPE

Distanziatore esagonale, Acciaio



RURt

Ruota girevole a foro centrale, Poliuretano -



BLM

Pressore liscio a molla, Corpo inox



DTR

Pignone tendicatena, Ruota dentata in



PM4

Ruota per vite senza fine, Bronzo

Prodotti correlati



PT881

Pignone di trazione, Serie 881



PR881

Ruota di rinvio, Serie 881



CAP880

Catena a tapparella, Stretta serie 880