



Side flexing slim plate chain **stainless steel**

Range 881 TAB

CAP881Tss

- **Bending radius allows chain to follow a curved path**

- **Materials:**

Plates: polished cold-laminated stainless steel (30HRC min.)

Pin: stainless steel 302 (1400N/mm²)

- **Operating temp.:** -40°C to +260°C (+120°C in humid environments)

- **Length** 3048mm (80 plates)

Associated products


- Drive sprocket **PT881**

- Idler sprocket **PR881**


- Idler **DBL880**

- Straight track **GRD880T**


- Curved track **GCB880T**

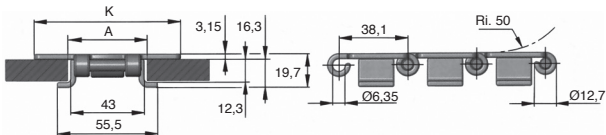

A $\left\{ \begin{array}{l} \text{Straight} - 46 \\ \text{Curved} - 44,5 \end{array} \right.$

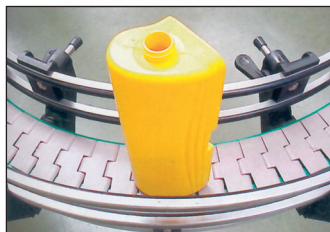

Typical application

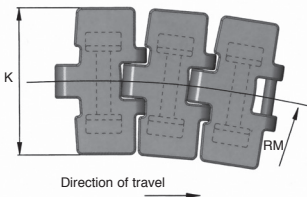

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius RM (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP881T-82/SS	82,5	3048	500	9500	2,9	205,85 €
CAP881T-114/SS	114,3	3048	500	9500	3,6	266,13 €

Dimensions in mm

Altri prodotti...



Forcella e perno serie corta, Corta inox



Snodo sferico, acciaio/acciaio autolubrificante



Ingranaggio dritto di precisione, Inox 316



Albero per riduttori E, Albero doppio per riduttori E




Piastrina con anello, Inox



Connettore / supporto per profili alluminio, Standard



Chain tool, Drive chain maintenance tools

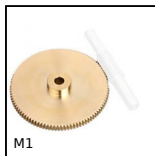

Ruota per vite senza fine, Bronzo



Conical flexible shaft handlee Ø22, Black PVC



Rinvio angolare a L, da 0.53 a 1.77



Motoriduttore AC asincrono da 0,18 a 0,55kW, 0.18 a



Guida lineare su binario Drylin® T, fino al 7000 N

Prodotti correlati



Pignone di trazione, Serie 881



Ruota di rinvio, Serie 881



Catena a tapparella, Stretta serie 880