



Side flexing slim plate chain **stainless steel**

Range 881 TAB

CAP881Tss

- **Bending radius allows chain to follow a curved path**

- **Materials:**

Plates: polished cold-laminated stainless steel (30HRC min.)

Pin: stainless steel 302 (1400N/mm²)

- **Operating temp.:** -40°C to +260°C (+120°C in humid environments)

- **Length** 3048mm (80 plates)



Associated products


- Drive sprocket **PT881**

- Idler sprocket **PR881**

- Idler **DBL880**

- Straight track **GRD880T**


- Curved track **GCB880T**

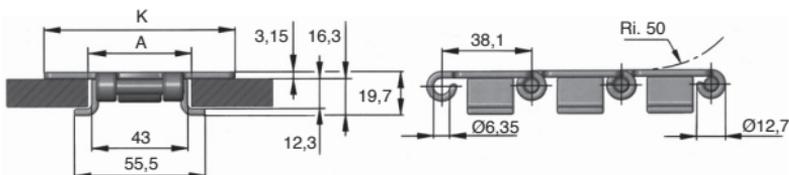

A $\left\{ \begin{array}{l} \text{Straight} - 46 \\ \text{Curved} - 44,5 \end{array} \right.$



Typical application

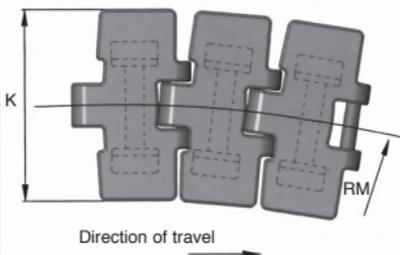

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius RM (mm)	Breaking load (N)	Weight (kg/m)	Price each 1 to 4
CAP881T-82/SS	82,5	3048	500	9500	2,9	205,85 €
CAP881T-114/SS	114,3	3048	500	9500	3,6	266,13 €

Dimensions in mm


Altri prodotti...



DOMI80
Kit di raccordo, Kit di raccordo XZ



DILC
Indexing plunger with cam, with cam

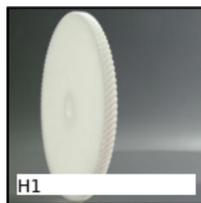

H1
Ingranaggio elicoidale ad assi incrociati a 90°, Plastica lavorata



MRA
Maglia rapida, Acciaio



DIV_SS
Pistoncino a molla, Bloccabile - Inox



BOXbeta
Box kit di spine beta, Box kit - beta



BPLF
Sfera portante alta sporgenza, Leggero



CHB
Riduttore a ruota e vite senza fine, fino a 73 Nm



SBS_L
Giunzione per catena al metro, Falsa maglia



PAS
Maniglia a ponte, Reinforced PA



PSG125
Ingranaggio dritto di precisione, Acciaio



EFTC
Supporto di fissaggio, Inox

Prodotti correlati



PT881
Pignone di trazione, Serie 881



PR881
Ruota di rinvio, Serie 881



CAP880
Catena a tapparella, Stretta serie 880