

Side flexing wide plate chain



CAP882T

Range 882 TAB

- **Bending radius allows chain to follow a curved path**

- **Materials:**

Plates: self lubricating brown acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- Length 3048mm (80 plates)



Advantages

- Special shape prevents products being carried moving or falling whilst on curves

Associated products

- Drive sprocket **PT882**

- Idler sprocket **PR882**

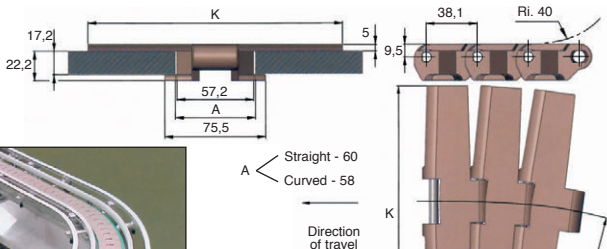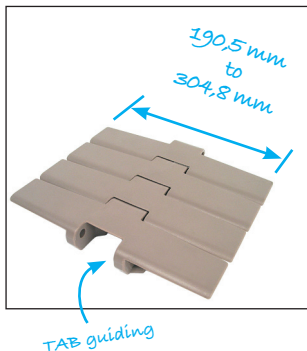

Typical application

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)	RM (mm)			
CAP882T-190	190,5	3048	610	8000	2,43	284,83 €	
CAP882T-254	254,0	3048	610	8000	2,87	296,96 €	
CAP882T-304	304,8	3048	610	8000	3,41	325,33 €	

Dimensions in mm

Altri prodotti...



RHT

Ruota alte temperature, fino a 200kg



CHAsb89

Cerniera senza perno,
□Cerniera in polimero



CHAFR

Cerniera, A frizione



PRF_PGN

Maniglia e battuta per porta, Maniglia con serratura



PCS_PA6

, 12.7mm (DIN 08B-1)



CHA38_SS

Cerniera su facciata ad avvitare inox, Su facciata



TAC_SS

Tenditore, Inox



GCH

Guida lineare a sfere - Sfere inox, Carello - da 514 N a 16700 N



KITbuh

Kit di motorizzazione 24V, Planetario



PPF

Pistoncino a molla, con flangia



BLHB30

Rinvio angolare ad albero cavo, fino a



PGM52-M4

Maniglia a ponte, Ottone

Prodotti correlati



PT882

Pignone di trazione, Serie 882



PR882

Ruota di rinvio, Serie 882