

Side flexing wide plate chain



CAP882T

Range 882 TAB

- Bending radius allows chain to follow a curved path

- Materials:

Plates: self lubricating brown acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- Length 3048mm (80 plates)



Advantages

- Special shape prevents products being carried moving or falling whilst on curves

Associated products


- Drive sprocket **PT882**

- Idler sprocket **PR882**

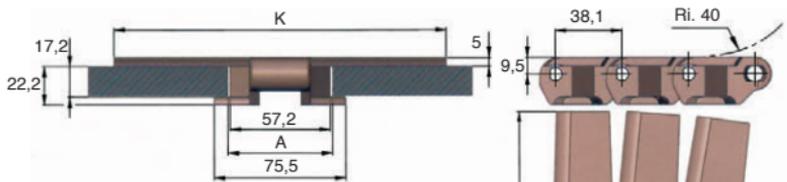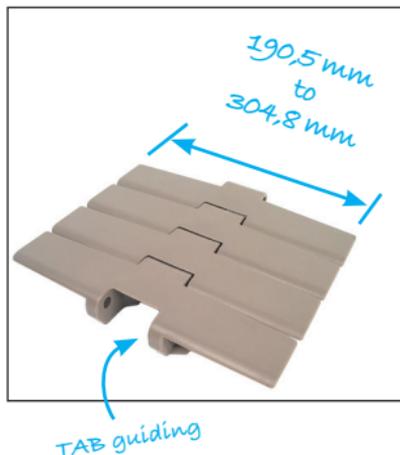

A $\left\{ \begin{array}{l} \text{Straight} - 60 \\ \text{Curved} - 58 \end{array} \right.$

Direction of travel

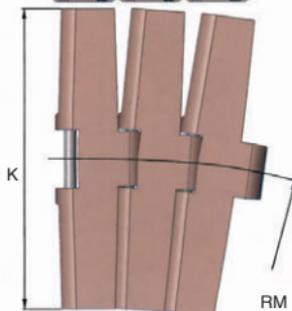

Typical application

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)	RM (mm)			
CAP882T-190	190,5	3048	610	8000	2,43	284,83 €	
CAP882T-254	254,0	3048	610	8000	2,87	296,96 €	
CAP882T-304	304,8	3048	610	8000	3,41	325,33 €	

Dimensions in mm

Altri prodotti...



PTA40
Articulated foot with
solid base foot Ø 40,
3000N



NPTF30
Morsetto di
collegamento,
Distanziale Ø14 a Ø20



VELM6
Supporto avvitabile
per rotolo a strappo
fermacavi,
Poliamide



KK
Chiavetta
rettangolare, Acciaio



PX_PO
Maniglia -
movimentazione
manuale, standard



DOMI120
Accessori di
collegamento, Leva di
serraggio



CFS
Perno folle mini,
Miniatura



BSM
Pressore a molla con
esagono incassato,
corpo e spina inox
303



PAMF80EB
Piede snodato con
base stampata
fissabile Ø80, Piede



FTSN
Albero supportato per
guida lineare, Albero
acciaio / supporto



NSR
Connettore rinvio
d'angolo, Regolabile



PRF-SRA
Sistema di chiusura
per profili alluminio,
Serrata

Prodotti correlati



PT882
Pignone di trazione,
Serie 882



PR882
Ruota di rinvio, Serie
882