

Side flexing wide plate chain



CAP882T

Range 882 TAB

- **Bending radius allows chain to follow a curved path**

- **Materials:**

Plates: self lubricating brown acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- Length 3048mm (80 plates)



Advantages

- Special shape prevents products being carried moving or falling whilst on curves

Associated products

- Drive sprocket **PT882**

- Idler sprocket **PR882**

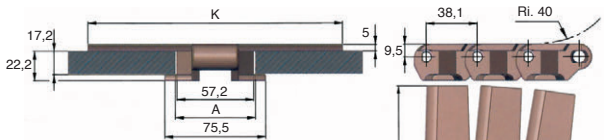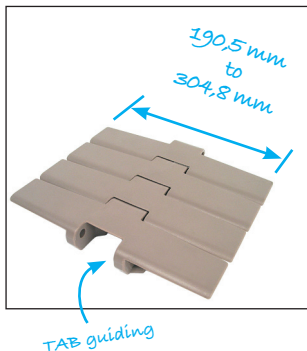


A $\left\{ \begin{array}{l} \text{Straight} - 60 \\ \text{Curved} - 58 \end{array} \right.$

Direction of travel



Typical application

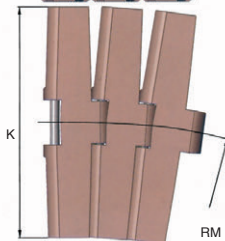

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)	RM (mm)			
CAP882T-190	190,5	3048	610	8000	2,43	284,83 €	
CAP882T-254	254,0	3048	610	8000	2,87	296,96 €	
CAP882T-304	304,8	3048	610	8000	3,41	325,33 €	

Dimensions in mm

Altri prodotti...



PW_PWG25
Vite senza fine di
precisione, Acciaio



SER69K-CLE
Chiusura 1/4 di giro
per agroalimentare,
Chiave



GSI
Molla a gas inox, Inox



LR
Cuscinetti a sfere -
Accessorio, Ghiera di
regolazione



EKN
Giunto a soffietto
Gerwah®, da 0.5 a
12Nm



RPCplss
Ruota girevole a
doppio bloccaggio,
Inox - poliammide




HTD14M_55
Puleggia dentata di
trasmissione tipo
HTD, HTD14 Acciaio



PTA80
Piede snodato con
base stampata Ø80,
10000N



DOG258
Motoriduttore DC 12V
e 24V DC, da 12 a
15 Nm

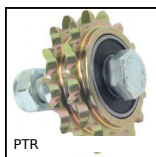

PTR
Pignone tendicateni,
Per applicazioni
correnti



CHA
Cerniera, Robusta -
Apertura 180°



UCP_PBT
Cuscinetto ritto
polimero inox,
polimero e inox

Prodotti correlati



PT882
Pignone di trazione,
Serie 882



PR882
Ruota di rinvio, Serie
882