

# Side flexing wide plate chain



## CAP882T

## Range 882 TAB

- Bending radius allows chain to follow a curved path

- Materials:

Plates: self lubricating brown acetal

Pin: stainless steel 304

- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)

- Length 3048mm (80 plates)



### Advantages

- Special shape prevents products being carried moving or falling whilst on curves

### Associated products


- Drive sprocket **PT882**

- Idler sprocket **PR882**

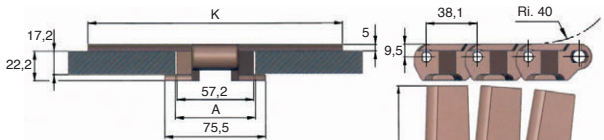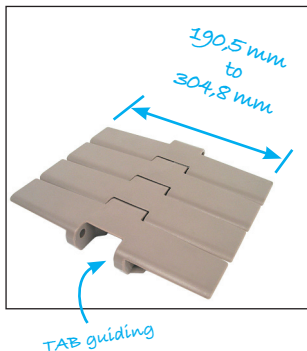

A  $\left\{ \begin{array}{l} \text{Straight} - 60 \\ \text{Curved} - 58 \end{array} \right.$

Direction of travel

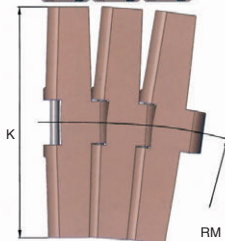

Typical application

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	Width K (mm)	Length (mm)	Bend radius		Breaking load (N)	Weight (kg/m)	Price each 1 to 4
			RM (mm)	RM (mm)			
CAP882T-190	190,5	3048	610	8000	2,43	284,83 €	
CAP882T-254	254,0	3048	610	8000	2,87	296,96 €	
CAP882T-304	304,8	3048	610	8000	3,41	325,33 €	

Dimensions in mm

## Altri prodotti...



FF20

Riduttore ad alberi paralleli, da 5.80 a 23 Nm



PCS50K

Pignone a catena dentatura temprata, 12.7mm (DIN08B-1)




P15

Riduttore a ruota e vite senza fine, fino a 3,75 Nm



PW\_PWG2

Vite senza fine di precisione, Inox

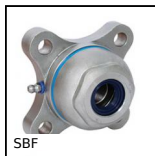

SBF

Open flange bearing unit for food industry, cover



H0

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2



RAGb

Cylindrical brush track, For gentle conveying and handling



DOG111

Motoriduttore DC 12V e 24V DC, da 1.5 a 6 Nm



UGPC

Unità di guida per cilindrico, Cuscinetto



PFM

Piede senza snodo, Lamiera modellata



UCP

Cuscinetto ritto in ghisa, Ghisa



PGB

Attrezzi, Porta attrezzi

## Prodotti correlati



PT882

Pignone di trazione, Serie 882



PR882

Ruota di rinvio, Serie 882