

Heavy duty plastic hinge, opens 180° New

 

CHA

Polyamide

- **Screw fixed hinge**
- Maximum opening: 180°
- Materials:
 - Black polyamide
 - Nickel plated steel pin

Applications

- Industrial bodywork

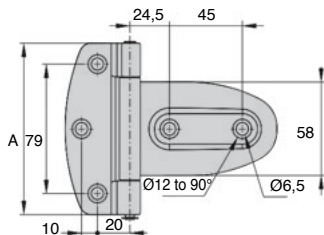

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Price each 1 to 5
CHA108-131	108	131	9,5	6	98	24,98 €

Dimensions in mm

Altri prodotti...



HW_HT
Guida su semi-binari,
Ruota



CHINV
Cerniera invisibile,
Invisibile - Apertura
fino a 90°



PGB
Attrezzi, Porta attrezzi



CHAE4080PA
Cerniera ad avvitare
estetica simmetrica,
Poliamide



PTA150
Piede snodato con
base stampata Ø150,
Ø 150



D19 D29
Molla di compressione
al metro acciaio, al
metro



PRF_ROUL_F
Ruota per profili
alluminio, Con freno



M0
Coppia ruota e vite
senza fine , Acciaio
temprato



G4-ECO
Ingranaggio dritto
acciaio - serie ECO,
Acciaio C45



TBEBASE10
Economic mini-table
with trapezoidal
lead screw, 1kg



DKGS
Giunto senza gioco
Gerwah®, da 0.5 a
3Nm



TBD
Tavola di
posizionamento a
passo inverso
manuale, 20kg

Prodotti correlati