

# Heavy duty plastic hinge, opens 180° New

 

## CHA

## Polyamide

- **Screw fixed hinge**
- Maximum opening: 180°
- Materials:
  - Black polyamide
  - Nickel plated steel pin

### Applications

- Industrial bodywork

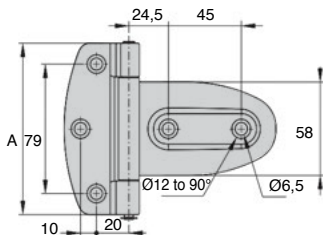

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Price each 1 to 5
CHA108-131	108	131	9,5	6	98	24,98 €

Dimensions in mm

## Altri prodotti...



LVT

Mini martinetto motorizzato 4A, 4 ampere



MPE

Distanziatore esagonale, Acciaio



PTA50

Piede snodato con base stampata Ø50, Ø 50



PTAF100-PAMF100

Piede fissabile con base lamiera Ø100, Ø 100



PRF-GUM

Attrezzi, Gomma



CHA1056-UPA

Cerniera su facciata in poliammide, Poliammide nera



CFES

Perno folle eccentrico, Eccentrico



ACLBMC

Supporto per sensore per profili alluminio, Porta cellula




MSP3815

Inserto con piastrina a incollare



PTA80ssEB

Piede snodato con base stampata Ø80,

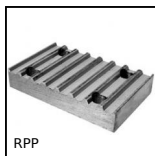

RPP

Piastra di giunzione per cinghia RPP, RPP8



SLB

Pistoncino a molla, inox

**Prodotti correlati**