
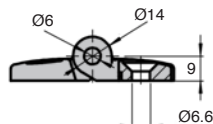
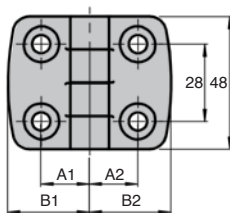


# Hinge for aluminium profile

3 materials available

CHA

- **Screw-on hinge**
- For aluminium profile 30x30mm, 40x40mm or 45x45mm (**PRF4545**)
- Opening angle 180° 180°
- Material:
  - 316 stainless steel leaves
  - Glass-fibre reinforced Black PA/Nylon
  - Cast aluminium
  - Stainless steel pin
  - PTFE bearing (Aluminium version only)
- Mount using **M6 FHC6** milled head screws

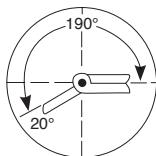

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	Net	-5%	-10%	On request

Part N°	A1	A2	B1	B2	FA max (N)	FR max (N)	Profile section	Weight (g)	Price each 1 to 5
<b>Stainless steel hinge</b>									
CHA35-48/SS	17,5	17,5	29,5	29,5	575	800	30x30	167	25,71 €
CHA45-48/SS	22,5	22,5	38,5	38,5	675	900	40x40	205	32,20 €
CHA50-48/SS	25,0	25,0	42,5	42,5	575	900	45x45	223	33,05 €
<b>Glass reinforced plastic hinge</b>									
CHA35-48/PA	17,5	17,5	29,5	29,5	400	700	30x30	36	4,45 €
CHA45-48/PA	22,5	22,5	38,5	38,5	450	750	40x40	43	4,03 €
CHA50-48/PA	25,0	25,0	43,5	43,5	450	750	45x45	46	4,13 €
<b>Aluminium hinge</b>									
CHA35-48/AL	17,5	17,5	29,5	29,5	225	325	30x30	65	12,19 €
CHA45-48/AL	22,5	22,5	38,5	38,5	250	400	40x40	69	14,42 €
CHA50-48/AL	25,0	25,0	43,5	43,5	250	400	45x45	73	14,61 €

All dimensions in mm

**Fax** 0 825 88 6000  
Service 0,15 € / min  
+ prix appel

cial2@hpceurope.com

**HPC**

SUPPLEMENT 2019

157

## Altri prodotti...



FIRSTDC1Q60

Variatore di velocità  
10A, 10 A



LRX

Guida lineare a rulli,  
Carello - da 9410 N a  
101000 N



ECF

Rivetto rivestito in  
gomma di fissaggio,  
Elastomero in  
cloroprene



M0

Coppia ruota e vite  
senza fine , Plastica  
lavorata (delrin)



GE14

Chiusura a leva, Con  
porta-lucchetto



PRF\_ER

Elementi di giunzione,  
Elemento di raccordo



CTZYSS

Antivibrante elastico  
inox sfolato, Inox



PLM-20SC

Magnete cilindrico di  
fermo filettato,  
Magnete di fermo  
maschiato



CSSSS

Snodo sferico inox,  
Inox/ PTFE



PLS

Distanziatore  
cilindrico, Inox 303



D-PAR\_SS

Piedino antivibrante  
parabolico, inox



M0

Coppia ruota e vite  
senza fine , Acciaio  
trattato

Prodotti correlati