
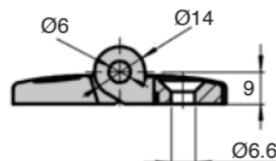
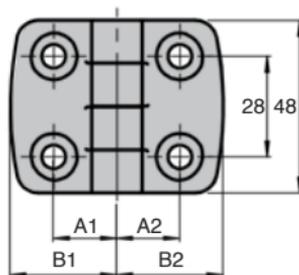


Hinge for aluminium profile

3 materials available

CHA

- **Screw-on hinge**
- For aluminium profile 30x30mm, 40x40mm or 45x45mm (**PRF4545**)
- Opening angle 180° 180°
- Material:
 - 316 stainless steel leaves
 - Glass-fibre reinforced Black PA/Nylon
 - Cast aluminium
 - Stainless steel pin
 - PTFE bearing (Aluminium version only)
- Mount using **M6 FHC6** milled head screws

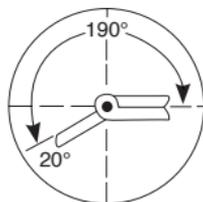

DISCOUNTS

| Qty | 1+ | 6+ | 20+ | 50+ |
|-------|-----|-----|------|------------|
| Disc. | Net | -5% | -10% | On request |

| Part N° | A1 | A2 | B1 | B2 | FA max (N) | FR max (N) | Profile section | Weight (g) | Price each 1 to 5 |
|---------------------------------------|------|------|------|------|---------------|---------------|--------------------|---------------|----------------------|
| Stainless steel hinge | | | | | | | | | |
| CHA35-48/SS | 17,5 | 17,5 | 29,5 | 29,5 | 575 | 800 | 30x30 | 167 | 25,71 € |
| CHA45-48/SS | 22,5 | 22,5 | 38,5 | 38,5 | 675 | 900 | 40x40 | 205 | 32,20 € |
| CHA50-48/SS | 25,0 | 25,0 | 42,5 | 42,5 | 575 | 900 | 45x45 | 223 | 33,05 € |
| Glass reinforced plastic hinge | | | | | | | | | |
| CHA35-48/PA | 17,5 | 17,5 | 29,5 | 29,5 | 400 | 700 | 30x30 | 36 | 4,45 € |
| CHA45-48/PA | 22,5 | 22,5 | 38,5 | 38,5 | 450 | 750 | 40x40 | 43 | 4,03 € |
| CHA50-48/PA | 25,0 | 25,0 | 43,5 | 43,5 | 450 | 750 | 45x45 | 46 | 4,13 € |
| Aluminium hinge | | | | | | | | | |
| CHA35-48/AL | 17,5 | 17,5 | 29,5 | 29,5 | 225 | 325 | 30x30 | 65 | 12,19 € |
| CHA45-48/AL | 22,5 | 22,5 | 38,5 | 38,5 | 250 | 400 | 40x40 | 69 | 14,42 € |
| CHA50-48/AL | 25,0 | 25,0 | 43,5 | 43,5 | 250 | 400 | 45x45 | 73 | 14,61 € |

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 € / min
+ prix appel

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

157

Altri prodotti...



SBS_L
Giunzione per catena
al metro, Maglia di
giunzione - inox




CLG1
Ingranaggio dritto in
plastica stampata ,
Nylon stampato



CHB
Single output shaft,
For CHB gearbox




STL
Guida con spazzola,
Binario

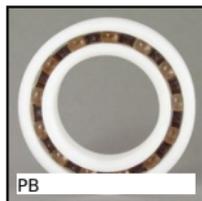

PB
Cuscinetto in plastica,
Plastica - materiale
sfere : vetro



CCL55
Capocorda ad
occhiello, Inox

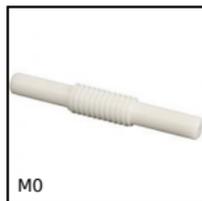

M0
Vite senza fine ,
Plastica lavorata
(delrin)



QN
Cuscinetto a singola
corona di rulli
cilindrici, Anello
esterno libero



ERT
Dado piastrina, Per
scanalatura a T



CHA35
Cerniera ad avvitare,
Hinge



GCB880
Guida curva, Serie
880 e 881



TCC_SS
Tenditore, Inox

Prodotti correlati