

# New Rectangular hinge, drilled or countersunk

For built-in doors

 


CHA

- Drilled or countersunk hinge

- Materials:

Stainless steel (304)

Natural finish

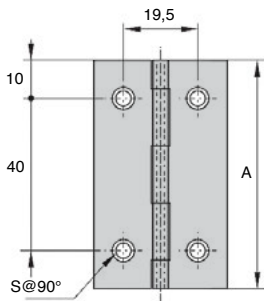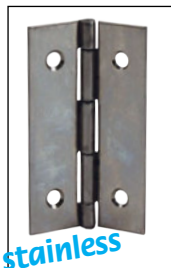

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	S	Type	Weight (g)	Price each 1 to 5
CHA60-35-F/SS	60	35	1	2	4	Countersunk	20	5,68 €
CHA60-35-P/SS	60	35	1	2	4	Drilled	20	5,68 €

Dimensions in mm

## Altri prodotti...



MSP3815

Inserito con piastrina a incollare Masterplate®, rettangolare con pe...




T5-16ECO

Puleggia dentata di posizionamento tipo T, Serie economica - T5 allu...




GPLso

Scovolo, seta

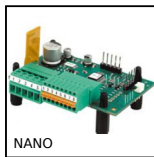

NANO

Variatore di velocità 3A, 3 A

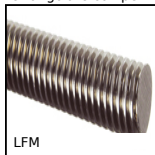

LFM

Vite trapezoidale acciaio, Acciaio semiduro - 1 filetto



OP2

Indicatore di posizione digitale (N. di giri), 3 cifre



M0

Coppia ruota e vite senza fine, Acciaio temprato



GGB

Dado ad alette, Cieco



CHM50

Riduttore a ruota e vite senza fine, fino a



NT61

Riduttore coassiale a treni paralleli, da 5 a



PTA150

Piede snodato con base stampata Ø150,



MDPOT

Potenziometro,

## Prodotti correlati



CHAC4040SS

Cerniera, Quadrata con rivetto e fori



CHAC4040NP

Cerniera, Quadrata con rivetto senza fori