

# New Rectangular hinge, drilled or countersunk

For built-in doors



CHA

- Drilled or countersunk hinge

- Materials:

Stainless steel (304)

Natural finish

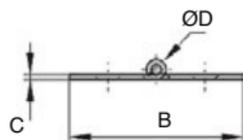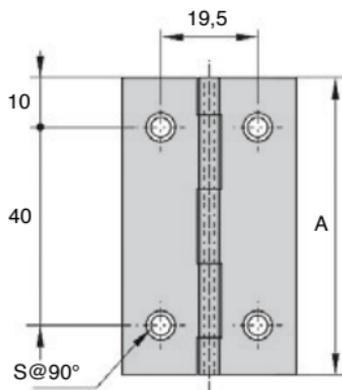

## DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	S	Type	Weight (g)	Price each 1 to 5
CHA60-35-F/SS	60	35	1	2	4	Countersunk	20	5,68 €
CHA60-35-P/SS	60	35	1	2	4	Drilled	20	5,68 €

Dimensions in mm

## Altri prodotti...



RJA00\_02

Guarnizione in gomma, Da agganciare



MSP38

Inserto con piastrina a incollare Masterplate®, Cilindrico Ø38 con...



Q3

Cuscinetto a doppia corona di sfere, Obliquo - Acciaio



TBE12

Economic mini-table with trapezoidal lead screw, 2kg



ZG0

Ingranaggio dritto in plastica, Plastica lavorata (delrin)



CHML50

Riduttore a ruota e vite senza fine, fino a 107 Nm - Con limitatore ...



AC156-157

Riscontro per chiusura a leva rigida ad anello, 25.5mm



HSS

Vite a spalla di precisione ISO7379, Acciaio trattato classe 12.9



BLHB50

Rinvio angolare ad albero cavo, fino a 30



GLB

Volantino a 6 lobi filettato,



VDSQCB

Bloccaggio scorrevole per la regolazione,



BFM2

Dado trapezoidale, Bronzo - 2 filetti

## Prodotti correlati



CHAC4040SS

Cerniera, Quadrata con rivetto e fori



CHAC4040NP

Cerniera, Quadrata con rivetto senza fori