

New Rectangular hinge, drilled or countersunk

For built-in doors

 

CHA

- Drilled or countersunk hinge

- Materials:

Stainless steel (304)

Natural finish

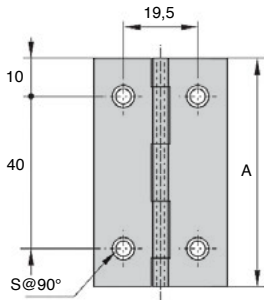

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	S	Type	Weight (g)	Price each 1 to 5
CHA60-35-F/SS	60	35	1	2	4	Countersunk	20	5,68 €
CHA60-35-P/SS	60	35	1	2	4	Drilled	20	5,68 €

Dimensions in mm

Altri prodotti...



ADL_F

Anello di sollevamento, Inox



SVT5

Martinetto a vite - Vite traslante, Vite traslante



SVT15

Martinetto a vite - Vite traslante, Vite traslante



NCT

Giunto di collegamento, Ad angolo fisso



PW_PWG1

Ruota di precisione, Bronzo



PSG05HC

Ingran. dritto di precisione trattato skiving, Acciaio 20NCD2 cement...



PGMT

Maniglia a ponte, Acciaio



CHA38_SS

Cerniera su facciata ad avvitare inox, Su facciata



MEB

Ingranaggio conico in plastica stampata, 1:1



R203

Molla per stampi ISO10243, Leggero



BCTH

Pomello a fungo Hygienic Usit®, Con foro filettato e collare



BABFCFO

Perno autobloccante, Boccole di fissaggio con flangia cilindrica

Prodotti correlati



CHAC4040SS

Cerniera, Quadrata con rivetto e fori



CHAC4040NP

Cerniera, Quadrata con rivetto senza fori