 



SteSta Square hinge with riveted pin, not drilled

For built in doors

CHAC-NP

- Riveted pin
- Material :
 - CHAC-NP: Steel hinge
 - CHAC-NP/SS: Stainless steel 304
- Brut finish

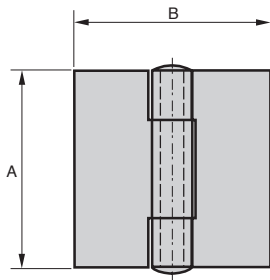

DISCOUNTS

Qty.	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each 1 to 5
Steel							
CHAC4040-NP	40	40	2	4	34	✓	8,69 €
CHAC5050-NP	50	50	2	6	61	✓	10,68 €
CHAC6060-NP	60	60	2	6	82	✓	11,80 €
Stainless steel							
CHAC4040-NP/SS	40	40	2	4	34	✓	14,69 €
CHAC5050-NP/SS	50	50	2	6	61	✓	16,85 €
CHAC6060-NP/SS	60	60	2	6	82	✓	19,03 €

*Depending on availability - Dimensions in mm

Altri prodotti...



HBM
Guida su semi-binari,
Boccola di regolazione



ZBconique
Ingranaggio conico in
plastica, 1:1



CHA_GC_9SS
Cerniera (tutto inox),
A saldare



OPFL_OPPM
Accessori per
indicatori, Pomello di
manovra



S2B
Supporto corto per
manicotto chiuso a
sfere, Chiuso - Corto



BEF
Vite a ricircolo di sfere
miniatura, Supporto
con cuscinetto



UTKswr
Guida lineare
Utilitrack®, Profilo
guida a V



ADL_F
Anello di
sollevamento, Acciaio



CHAu
Cerniera ad avvitare,
270°



PSG25S
Ingranaggio dritto di
precisione, Inox 303



G3
Ingranaggio dritto
acciaio, Acciaio



BSB
Vite a ricircolo di
sfere, Supporto

Prodotti correlati



CHAC4040NP
Cerniera, Quadrata
con rivetto senza fori



CHAC4040SS
Cerniera, Quadrata
con rivetto e fori