 

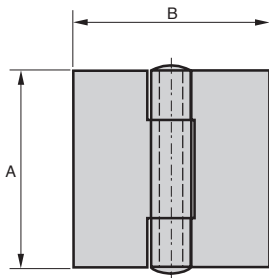


SteSta Square hinge with riveted pin, not drilled

For built in doors

CHAC-NP

- Riveted pin
- Material :
 - CHAC-NP: Steel hinge
 - CHAC-NP/SS: Stainless steel 304
- Brut finish

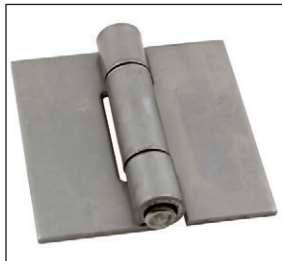

DISCOUNTS

Qty.	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each 1 to 5
Steel							
CHAC4040-NP	40	40	2	4	34	✓	8,69 €
CHAC5050-NP	50	50	2	6	61	✓	10,68 €
CHAC6060-NP	60	60	2	6	82	✓	11,80 €
Stainless steel							
CHAC4040-NP/SS	40	40	2	4	34	✓	14,69 €
CHAC5050-NP/SS	50	50	2	6	61	✓	16,85 €
CHAC6060-NP/SS	60	60	2	6	82	✓	19,03 €

*Depending on availability - Dimensions in mm

Altri prodotti...



MAC

Moschettone DIN5299
acciaio, Acciaio



PTAF80-PAMF80

Piede fissabile con
base lamiera Ø80, Ø
80



RAGFLOW

Rotaia a rulli
Floway2®, Rotaia a
rulli



ACL-APB

Sistema di chiusura,
Fermporta magnetico



CAP881

Catena a tapparella,
Stretta serie 881



CHMR40

Riduttore a ruota e
vite senza fine, fino a
57 Nm



BUH77

Motoriduttore DC 12V
e 24V DC, da 0.1 a 2
Nm



BIM

Pistoncino a molla,
miniatura



EPRC

Dado cilindrico a
passo lungo, Dado
cilindrico-fino a 40mm



AT5P_AT10P

Piastra di giunzione
per cinghia AT, AT10



J52

Riduttore coassiale a
treni paralleli, da 0.27
a 0.90 - a treni para...



PM2

Coppia ruota e vite
senza fine, Plastica
lavorata (delrin)

Prodotti correlati



CHAC4040NP

Cerniera, Quadrata
con rivetto senza fori



CHAC4040SS

Cerniera, Quadrata
con rivetto e fori