 



# Ste Sta Square hinge with riveted pin, not drilled

For built in doors

CHAC-NP

- Riveted pin
- Material :
  - CHAC-NP: Steel hinge
  - CHAC-NP/SS: Stainless steel 304
- Brut finish

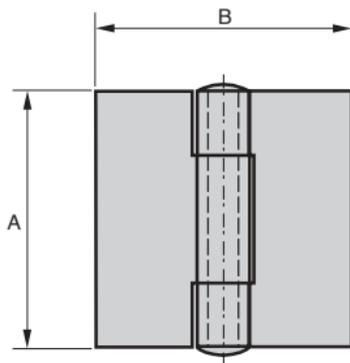


## DISCOUNTS

Qty.	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each 1 to 5
<b>Steel</b>							
CHAC4040-NP	40	40	2	4	34	✓	8,69 €
CHAC5050-NP	50	50	2	6	61	✓	10,68 €
CHAC6060-NP	60	60	2	6	82	✓	11,80 €
<b>Stainless steel</b>							
CHAC4040-NP/SS	40	40	2	4	34	✓	14,69 €
CHAC5050-NP/SS	50	50	2	6	61	✓	16,85 €
CHAC6060-NP/SS	60	60	2	6	82	✓	19,03 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...

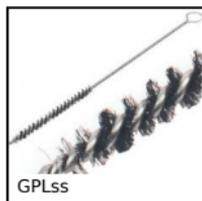

GPLss

Scovolo, inox



PRF\_BP

Maniglia e battuta per porta, Arresto per porta a battente



RURT

Ruota girevole a foro centrale, Poliuretano - Mozzo alluminio (Ultra...



LRR-53

Chiavistello con bloccaggio, Lucchetto a molla acciaio



CHML40

Riduttore a ruota e vite senza fine, fino a 57 Nm - Con limitatore d...



LWL

Guida lineare a sfere - Sfere inox, Binario - da 514 N a 16700 N



PRS50

Piede snodato tutto inox Ø50, Ø 50



SRG

Chiusura a leva regolabile, Corsa da 96mm a 121,7mm



SBRtool

Chain tool, Drive chain maintenance tools




CHA1056\_U4

Cerniera ad avvitare, Sezione 40X40



EBM

Cavallotto in acciaio, Acciaio

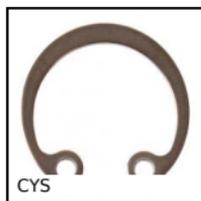

CYS

Anello di arresto interno DIN472, interno DIN 472

## Prodotti correlati



CHAC4040NP

Cerniera, Quadrata con rivetto senza fori



CHAC4040SS

Cerniera, Quadrata con rivetto e fori