 

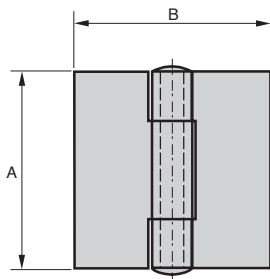


SteSta Square hinge with riveted pin, not drilled

For built in doors

CHAC-NP

- Riveted pin
- Material :
 - CHAC-NP: Steel hinge
 - CHAC-NP/SS: Stainless steel 304
- Brut finish

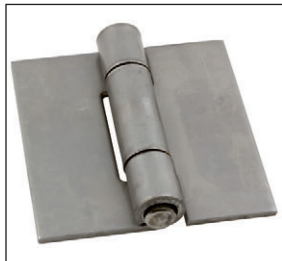

DISCOUNTS

Qty.	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each 1 to 5
Steel							
CHAC4040-NP	40	40	2	4	34	✓	8,69 €
CHAC5050-NP	50	50	2	6	61	✓	10,68 €
CHAC6060-NP	60	60	2	6	82	✓	11,80 €
Stainless steel							
CHAC4040-NP/SS	40	40	2	4	34	✓	14,69 €
CHAC5050-NP/SS	50	50	2	6	61	✓	16,85 €
CHAC6060-NP/SS	60	60	2	6	82	✓	19,03 €

*Depending on availability - Dimensions in mm

Altri prodotti...



TBD

Tavola di
posizionamento a
passo inverso
manuale, 40kg



HTD5M_15

Puleggia dentata di
trasmissione tipo
HTD, HTD5 Alluminio



NTM

Grano punta in nylon,
punta in nylon




RPCplss

Ruota girevole con
piastra, Inox -
Poliammide




HG5-ECO

Ingranaggio dritto
acciaio - serie ECO,
Acciaio C45

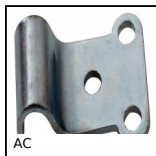

AC

Piastrina di riscontro,
15mm

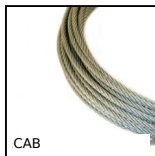

CAB

Cavo di fissaggio, Inox



BTE

Tenditore automatico
universale, Per
applicazioni correnti



MSP19

Inserto con piastrina a
incollare



PSG155

Ingranaggio dritto di
precisione, Inox 316



CHM40-MOT

Motoriduttore AC
asincrono da 0,18 a



WINGbr

Vite ad alette DIN316,
Ottone DIN 316

Prodotti correlati



CHAC4040NP

Cerniera, Quadrata
con rivetto senza fori



CHAC4040SS

Cerniera, Quadrata
con rivetto e fori