

Square hinge with riveted pin, drilled Eco

CHAC Sheet metal with rolled knuckle

 

- Hinge for plug door
- Riveted pin, half swaged
- Material:
Stainless steel 304
- Natural finish

stainless steel



Advantages

- Economic hinge

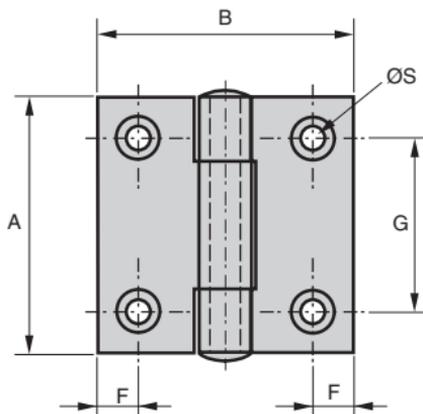

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	F	G	ØS	Weight (g)	Stock*	Price each 1 to 5
CHAC4040/SS	40	40	2	4	8	24	3,5	34	✓	14,69 €
CHAC5050/SS	50	50	2	6	8	34	4,0	61	✓	17,45 €
CHAC6060/SS	60	60	2	6	8	40	4,0	82	✓	19,89 €

*Depending on availability - Dimensions in mm



 

Square hinge with riveted pin, **not drilled**

Sheet metal with rolled knuckle **CHAC-NP**

- Hinge for plug door
- Riveted pin, leaves not offset
- Material:
 - CHAC-NP:** Steel hinge
 - CHAC-NP/SS:** Stainless steel 304
- Natural finish

Advantages

- Economic hinge

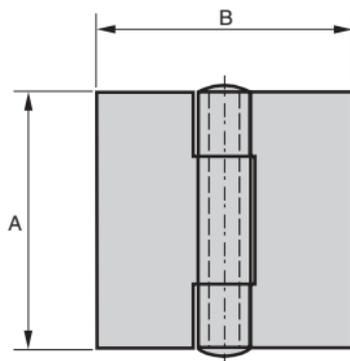

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Weight (g)	Stock*	Price each
						1 to 5	
Steel							
CHAC4040-NP	40	40	2	4	34	✓	8,69 €
CHAC5050-NP	50	50	2	6	61	✓	10,68 €
CHAC6060-NP	60	60	2	6	82	✓	11,80 €
Stainless steel							
CHAC4040-NP/SS	40	40	2	4	34	✓	14,69 €
CHAC5050-NP/SS	50	50	2	6	61	✓	16,85 €
CHAC6060-NP/SS	60	60	2	6	82	✓	19,03 €

*Depending on availability - Dimensions in mm

Altri prodotti...



CHINV
Cerniera invisibile,
Invisibile - Apertura
fino a 90°



PAP
Maniglia e battuta per
porta, Maniglia
ergonomica



CF
Perno folle, Standard -
acciaio



HTD8M-BAR
Barra dentata per
cinghia RPP, HTD8



PDM_PDV
Detectable plastic
palm grip, by metal
detectors



PM4
Ruota per vite senza
fine, Bronzo



PCS_PA6
, 9.525mm (DIN
06B-1)



RPCtc
Ruota girevole a foro
centrale, Acciaio -
Poliammide



T5P_T10P
Piastra di giunzione
per cinghia T, T5



DBL821
Rotella per catena,
Serie 821



SC2
Giunto rigido in 2
parti, Ganascia di
serraggio



VQT
Chiusura ¼ di giro per
bloccaggio, Manopola
plastica o inox

Prodotti correlati



CHAC4040NP
Cerniera, Quadrata
con rivetto senza fori



CHA60
Cerniera,
 Rettangolare forata o
con fori svasati