

Stylish stainless steel screw hinge

CHAESS

316 stainless steel



- Screw hinge
- For right and left mounting
- 180° opening angle
- Fixed using countersunk screws (M5, M6 or M8 according to DIN 7991)
- The visible surface of the hinge has polished satin finish
- Material:
100% 316 stainless steel

Advantages

- Stylish visual appearance as the pin is not visible
- Vibration proof
- Vandal proof thanks to welds over the pin at both ends.

Pin non-accessible

Impenetrable

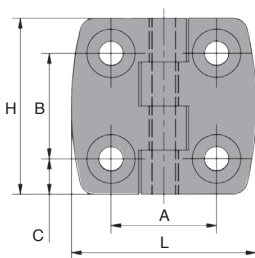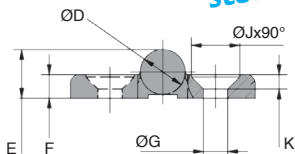

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	H	L	A	B	C	ØD	E	F	K	ØG	ØJ	Stock*	Price each 1 to 5
CHAE4042/SS	40	42	25	25	7,5	10,2	10,6	5	3,0	5,2	10,2	✓	30,86 €
CHAE5050/SS	50	50	30	30	10,0	12,0	12,5	6	3,7	6,2	12,4	✓	34,87 €
CHAE6063/SS	60	63	36	36	12,0	15,3	16,6	8	4,9	8,3	16,5	-	41,75 €

All dimensions in mm

Altri prodotti...



BLHT70

Rinvio angolare a T,
da 26 a 128 Nm




PCLA_T

Maniglia a ripresa,
Plastica



SEV

Attrezzo di bloccaggio
a tirante, A tirante
verticale - acciaio

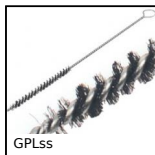

GPLss

Scovolo, inox



VTLF

Volantino a 3 lobi,
Poliammide - Ottone



DOMI30

Accessori di
collegamento, Piatto
girevole



NDS20

Connettore di
serraggio, Incrociata



ACLEFS

Elementi di
ancoraggio, Standard



PM3

Coppia ruota e vite
senza fine, Acciaio
non temprato



MRASeco

Maglia rapida
economica, Inox



Q6

Cuscinetto radiale a
sfere, Acciaio



SH4

Ingranaggio elicoidale
ad assi paralleli,
Acciaio 20NCD2

Prodotti correlati



CHAE3030PA

Cerniera ad avvitare
estetica quadrata,
Poliammide



CHAE6555

Cerniera ad avvitare
estetica, Alluminio



CHAEpac

Square decorative
screwed hinges,
carbon fibre
reinforced



CHA1056_U4

Cerniera ad avvitare,
Sezione 40X40