

# Adjustable friction hinges

New




## CHAFR For opening and positioning a panel or door

- Screw mounting
- Materials :
  - Aluminium
  - Sleeve : POM
  - Adjustable screw : Stainless steel A2
- Plain or black anodised finish
- Holding force : 0 to 5 Nm max
- Withstands 6000N
- Shear force : 5000N
- Working temp range -20 to 80°C

### Advantages

- Adjustable holding force

**NEW!**

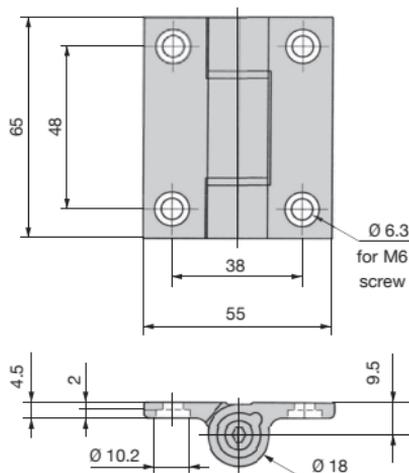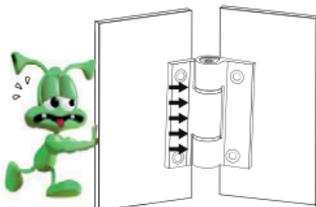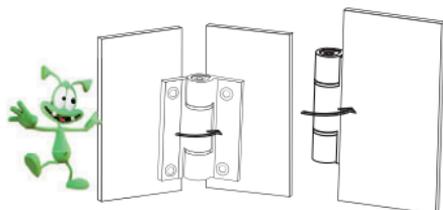

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	Finish	Price each 1 to 5
CHAFR6555/AI	Plain anodised	21,75 €
CHAFR6555/AN	Black anodised	21,75 €

Dimensions in mm

## Altri prodotti...



PDM\_PDV

, by metal detectors



PRFRTR

Elementi di giunzione,  
Giunto di collegamento  
trasversale



BABV

Ball lock pins lockable  
, Stainless steel



EHD06

Riduttore coassiale,  
da 8 a 19 Nm



PF30NM

Riduttore a ruota e  
vite senza fine, fino a  
8.8 Nm



MPS

Distanziatore  
esagonale, Inox 303



DOMI80

Kit di raccordo, Kit di  
raccordo XZ




NCT

Giunto di  
collegamento, Ad  
angolo fisso




RCC\_RCX

Rondella sferica -  
DIN6319, convessa

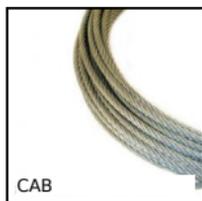

CAB

Cavo di fissaggio, Inox

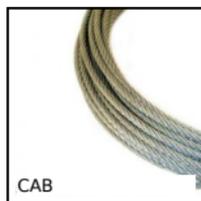

CAB

Cavo di fissaggio,  
Acciaio galvanizzato



D-PAR\_SS

Piedino antivibrante  
parabolico, inox

## Prodotti correlati



CHAR5050\_Z

Cerniera a molla,  
avvitabile



CHAC4040SS

Cerniera, Quadrata  
con rivetto e fori



CHAFR-MINI

Cerniera, A frizione



CHAFR-MINI

Cerniera, A frizione