

Adjustable friction hinges

New



 

CHAFR For opening and positioning a panel or door

- **Screw mounting**
- **Materials :**
 - Aluminium
 - Sleeve : POM
 - Adjustable screw : Stainless steel A2
- Plain or black anodised finish
- Holding force : 0 to 5 Nm max
- Withstands 6000N
- Shear force : 5000N
- Working temp range -20 to 80°C

Advantages

- Adjustable holding force

NEW!

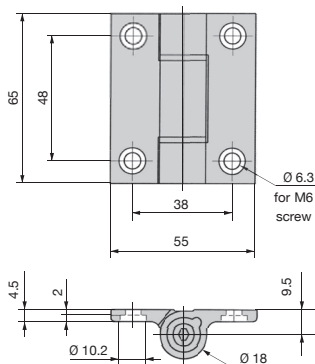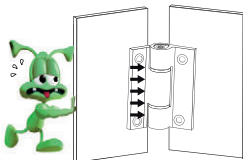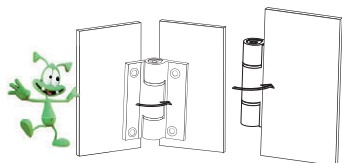

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	Finish	Price each 1 to 5
CHAFR6555/AI	Plain anodised	21,75 €
CHAFR6555/AN	Black anodised	21,75 €

Dimensions in mm

Altri prodotti...



HLC24

Rinvio angolare a dentatura spiroidale, Fino a 78Nm




OPFL_OPPM

Accessorio per indicatori, Flangia blocco albero



UTKswc

Guida lineare Utilitrack®, Ruota di precisione a V in acciaio

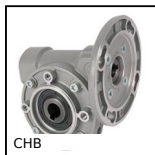

CHB

Riduttore a ruota e vite senza fine, fino a 41 Nm



PR40

Piede fissabile con snodo - poliammide, Ø 40



RPP

Piastra di giunzione per cinghia RPP, RPP14



DBL820

Rotella per catena, Serie 820 e 815



PTA50ssEB

Piede snodato con base stampata Ø50, Piede snodato



RFV40

Riduttore inox a ruota e vite senza fine, fino a 47 Nm



PMC48_M8

Supporto antivibrante a campana, Piastra a base ovale



UCP_SS

Cuscinetto ritto tutto inox, Inox



BPVMss

Sfera portante avvitabile miniatura, Miniatura ad avvitare

Prodotti correlati



CHAR5050_Z

Cerniera a molla, avvitabile



CHAC4040SS

Cerniera, Quadrata con rivetto e fori



CHAFR-MINI

Cerniera, A frizione



CHAFR-MINI

Cerniera, A frizione