

Adjustable friction hinges

New



 

CHAFR For opening and positioning a panel or door

- **Screw mounting**
- **Materials :**
 - Aluminium
 - Sleeve : POM
 - Adjustable screw : Stainless steel A2
- Plain or black anodised finish
- Holding force : 0 to 5 Nm max
- Withstands 6000N
- Shear force : 5000N
- Working temp range -20 to 80°C

Advantages

- Adjustable holding force

NEW!

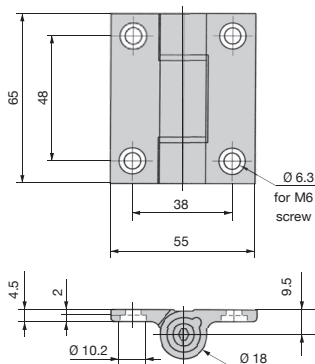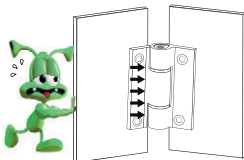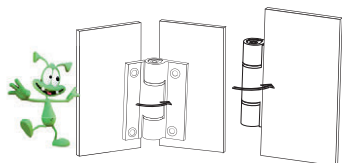

DISCOUNTS

Qty	1+	6+	20+	50+
Disc. List	-5%	-10%	On request	

Part number	Finish	Price each 1 to 5
CHAFR6555/AI	Plain anodised	21,75 €
CHAFR6555/AN	Black anodised	21,75 €

Dimensions in mm

Altri prodotti...



RPCpl

Ruota girevole a doppio bloccaggio, Acciaio - poliammide



PRF JL4

Panel accessories, Guarnizione - Ø 4mm



COA-COG

Staffa di montaggio per molla a gas, Staffa di montaggio piana per f...



GG2

Ingranaggio dritto rettificato, Acciaio trattato



CHAR5050_Z

Cerniera a molla, avvitabile



SLB

Pistoncino a molla, inox



BCA

Ghiera scanalata cilindrica in acciaio, Acciaio



D19 D29

Molla di compressione al metro acciaio, al metro



GARDLL

Bussola portamaschi, Acciaio o InoxInox



PTAF100-PAMF100

Piede fissabile con base lamiera Ø100, Ø 100



UGH32

Unità di guida tipo H, Per martinetti Ø 32



VEL

Rotolo a strappo fermacavi, cavi elettrici e pneumatici

Prodotti correlati



CHAR5050_Z

Cerniera a molla, avvitabile



CHAC4040SS

Cerniera, Quadrata con rivetto e fori



CHAFR-MINI

Cerniera, A frizione



CHAFR-MINI

Cerniera, A frizione