

## CHARCAV

## Very easy to install

- Spring-loaded hinges with stopper to lock the hinges in the open position for easy assembly

- 270° opening angle

- Material

304 stainless steel, stainless steel spring

- Spring torque

Opening spring:

M(0°): 1.6 Nm

M(90°): 1.2 Nm

M(180°): 0.84 Nm

Closing spring:





M(0°): 0.75 Nm

M(90°): 1.2 Nm

M(180°): 1.65 Nm

### Info

- Spring hinge opens or closes delivered flat

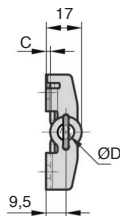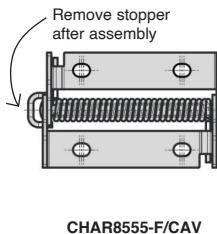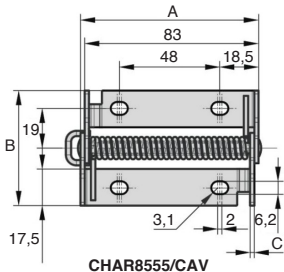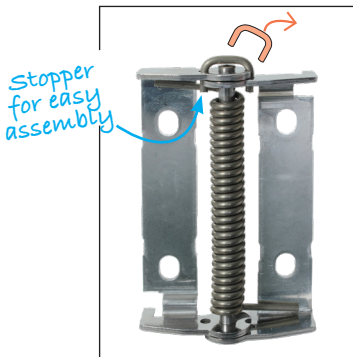

### DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	A	B	C	ØD	Type	Weight (g)	Stock*	Price each 1 to 5
CHAR8555/CAV	85	55	2	5	opening	107	-	23,33 €
CHAR8555-F/CAV	85	55	2	5	closing	107	-	23,33 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



PPD

Pistoncino a molla,  
Per lamiera



NTM

Grano punta in nylon,  
punta in nylon



LFM2

Vite trapezoidale  
acciaio, Acciaio  
semiduro - 2 filetti



BAGSS

Anello di bloccaggio  
inox, Inox



ADL\_M

Anello di  
sollevamento, Acciaio




MBF

Manicotto filettato di  
bloccaggio, Montaggio  
e regolazione rapidi



CLG1

Ingranaggio dritto in  
plastica stampata ,  
Nylon stampato

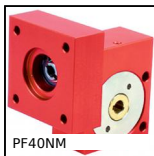

PF40NM

Riduttore a ruota e  
vite senza fine, fino a  
18 Nm




SHW

Rondella semplice ,  
Acciaio




BSM\_LOK

Pressore a molla con  
esagono incassato,

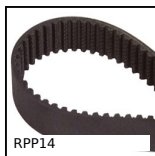

RPP14

Cinghia di  
trasmissione RPP,

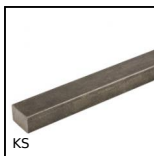

KS

Chiavetta in barre,  
Acciaio - in barre

## Prodotti correlati



CHAR7530

Cerniera a molla,  
saldabile



CHAR6035

Cerniera a molla,  
avvitabile e saldabile



CHAR7520

Cerniera a molla,  
avvitabile



CHAR16046

Cerniera a molla,  
avvitabile