

## CLAUSS

## Hygienic Usit®

### - Indexing lever with female thread and collar for a sealing washer

- EHEDG certification

- Material:

Stainless steel 1.4404 (316L)

Polished finish up to Ra<0.04

### Advantages


- Intended for use in hygienic environments. The completely sealed handle and a gasket prevent contamination inside the lever.
- In addition, the insert is fitted with a conical insert so that the screwed connection can be hygienically sealed to the sealing washer.
- The lever rotates freely when not in use.



### Accessory

- RDE sealing washers (cf. pages 37 à 39)

Apply pressure to engage the lever (safety feature)

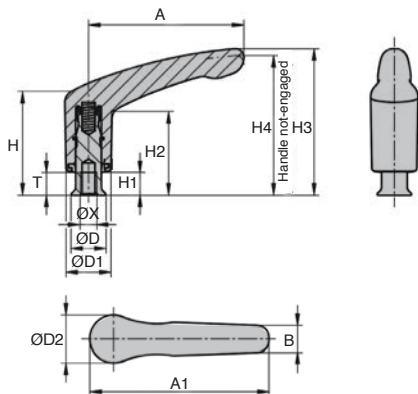

### DISCOUNTS

Qty	1+	5+	10+
Disc. Net	-5%		On request

Part N°	ØX	T	ØD	ØD1	ØD2	H	H1	H2	H3	H4	A	A1	B	N° of teeth	Price each
															1 to 4
CLA03M8/HUSS	M8	12	18	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	68,92 €
CLA03M10/HUSS	M10	15	22,3	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	69,96 €

All dimensions in mm

## Altri prodotti...



Vite a ricircolo di sfere, Supporto



Morsetto porta guide, Conico singolo



Cuscinetto assiale a rulli cilindrici, Acciaio



Rullo folle, Acciaio



Rinvio angolare, fino a 1.77 Nm



Attrezzo di montaggio per calettatori, Per calettatori di bloccaggio



Supporto piede, Per piedi o ruote



Maniglia a ponte, Fino a 250°C



Magnete cilindrico di fermo, Magnete di



Vite di regolazione per molla a gas, Vite di




Ingranaggio conico in plastica stampata, 2:1



Maniglia a ripresa - maschio, Inox

## Prodotti correlati

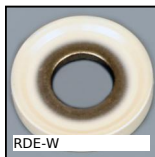

Rondella di tenuta Hygienic Usit®, Inox - EPDM bianco



Rondella di tenuta Hygienic Usit®, Stainless steel - EPDM blu



Maniglia a ripresa Hygienic Usit®, Inox