

- Indexing lever with male thread and collar for a sealing washer

- EHEDG certification
- Material:
Stainless steel 1.4404 (316L)
Polished finish up to Ra<0.04

Advantages


- Intended for use in hygienic environments. The completely sealed handle and a gasket prevent contamination inside the lever.
- In addition, the insert is fitted with a conical collar so that the screwed connection can be hygienically sealed to the sealing washer.
- The lever rotates freely when not in use.

Accessory

- RDE sealing washers
(cf. pages 37 à 39)



Apply pressure to engage the lever (safety feature)

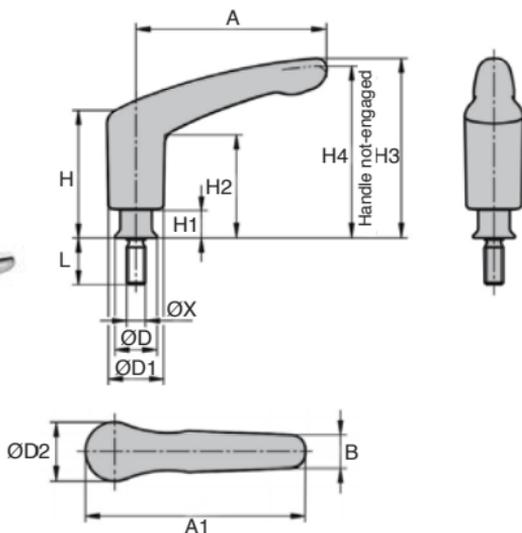

DISCOUNTS

Qty	1+	5+	10+
Disc.	Net	-5%	On request

Part N°	ØX	L	ØD	ØD1	ØD2	H	H1	H2	H3	H4	A	A1	B	N° of teeth	Price each
															1 to 4
CLA03T8/HUSS	M8	30	18	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	71,61 €
CLA03T10/HUSS	M10	40	22,3	23,6	24,9	54,7	12,1	44	77	73,5	81,5	94	14,2	20	75,22 €

All dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Altri prodotti...



BPHT

Sfera portante
fissaggio con perno
filettato, Forte



SHN

Dado esagonale -
DIN934, Acciaio (Class
6[8])



PRF_P

Elementi di
ancoraggio, Base di
ancoraggio



BOX-TOR-TOOL

Valigetta di
guarnizioni toriche in
nitrile, Extraction
tools




SUA4_L

Giunzione per catena
al metro, Maglia di
giunzione - acciaio



SSDB

Ingranaggio conico
inox, 2:1

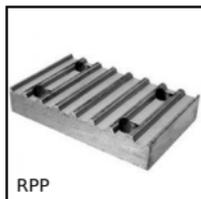

RPP

Piastra di giunzione
per cinghia RPP, RPP8



SVR30

Martinetto a vite - Vite
rotante, Con
madrevite esterna



AHEX

Riduttore manuale,
Barra esagonale




IBJ

Snodo angolare a
180°, Acciaio



RT25


Calettatore di
bloccaggio, Coppia
media/elevata

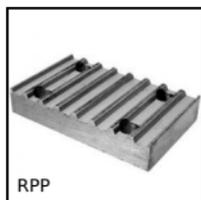

RPP

Piastra di giunzione
per cinghia RPP,
RPP14

Prodotti correlati

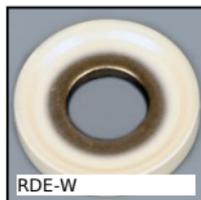

RDE-W

Rondella di tenuta
Hygienic Usit®, Inox -
EPDM bianco



RDE-B

Rondella di tenuta
Hygienic Usit®,
Stainless steel - EPDM
blu



CLA

Maniglia a ripresa
Hygienic Usit®, Inox