



Protective inserts for combination spanner

Hygienic Usit® and Hygienic Design® CMHDCO CMHDCF


- Protective inserts to be used with the CM combination spanner for mounting Hygienic Usit® and Hygienic Design® products

- Material:

Inserts: AlSi1MgMn

Advantages

- The protective caps have been specifically designed for fastening and un-fastening screwed connections with delicate surfaces.
- The protective caps will safely avoid the risk of contact corrosion with stainless steel screwed connections.
- The inserts are made of aluminium alloy EN AW 602 – a special aluminium suitable for contact with foodstuffs
- The protective cap is safely held in the spanner thanks to its special form and a sprung clip.

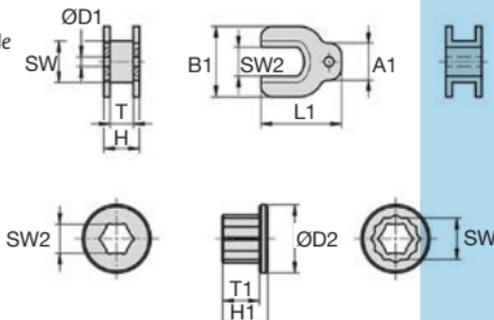

DISCOUNTS

Qty	1+	5+	10+
Disc.	Net	-5%	On request

Part N°	For spanner	SW	SW2	A1	B1	ØD1	ØD2	L1	T	T1	H	H1	Price each
													1 to 4
For open-ended spanner													
CM-10/HD/CF	CM-10/HD	10	7	9	17	2,3	-	19,4	5,6	-	8,6	-	18,84 €
CM-11/HD/CF	CM-11/HD	11	8	9	18	2,3	-	20,7	5,7	-	8,7	-	18,84 €
CM-13/HD/CF	CM-13/HD	13	10	10	22	3	-	23,2	6,7	-	10,7	-	19,05 €
CM-16/HD/CF	CM-16/HD	16	13	13	27	3	-	28,6	7,7	-	11,7	-	20,38 €
CM-19/HD/CF	CM-19/HD	19	16	13	30	4	-	32,5	8,6	-	12,6	-	21,54 €
CM-21/HD/CF	CM-21/HD	21	18	13	32	4	-	35,0	9,0	-	13,0	-	21,76 €
CM-27/HD/CF	CM-27/HD	27	24	14	40	4	-	43,8	10,8	-	15,0	-	23,26 €
For ring spanner													
CM-10/HD/CO	CM-10/HD	10	7	-	-	-	17	-	-	8,0	-	11,0	13,11 €
CM-11/HD/CO	CM-11/HD	11	8	-	-	-	18	-	-	9,4	-	11,4	13,11 €
CM-13/HD/CO	CM-13/HD	13	10	-	-	-	21	-	-	11,0	-	13,0	13,80 €
CM-16/HD/CO	CM-16/HD	16	13	-	-	-	25	-	-	12,4	-	14,4	14,15 €
CM-19/HD/CO	CM-19/HD	19	16	-	-	-	30	-	-	14,5	-	16,5	15,33 €
CM-21/HD/CO	CM-21/HD	21	18	-	-	-	32	-	-	14,7	-	16,7	15,43 €
CM-27/HD/CO	CM-27/HD	27	24	-	-	-	41	-	-	17,0	-	19,0	17,30 €

All dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

63

Altri prodotti...



SER69K

Chiusura 1/4 di giro per agroalimentare, Inox



CHAM52705S

Cerniera ad avvitare inox, Marine



GG1

Ingranaggio dritto rettificato, Acciaio trattato



RBNpl

Ruota fissa con piastra, Acciaio - caucciù



PR105

Piede fissabile con snodo - poliammide, Ø 103



AT5M AT10M

Cinghia aperta al metro tipo AT, AT10 Poliuretano armatura in acciaio



PRF1945

Profilato alluminio standard, 19 x 45 mm



UGAC_UGET

Guida per cilindrico, Ghiera per stelo filettato del martinetto



PPC55

Piastrina con anello, Inox



SLS

Supporto per vite trapezoidale,



G4

Ingranaggio dritto acciaio, Acciaio



CFS

Perno folle mini, Miniatura

Prodotti correlati



CM

Attrezzi Hygienic Usit® and Hygienic Design®, Protective inserts f...



CM_CO

Attrezzi Hygienic Usit® and Hygienic Design®, Protective inserts f...