



Stainless steel folding bracket

For heavy loads



CPAS

- **Folding bracket**
- Automatic locking when in the open position
- Opening sens to the top
- Unlocking lever
- Materials:



Stainless steel 304 polished finish

Advantage

- Angle bracket with integrated hinge function

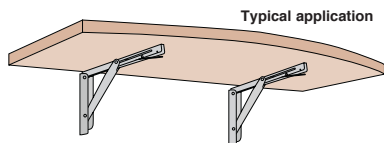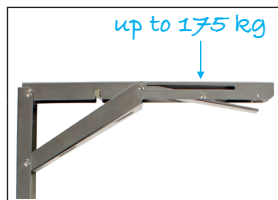

Typical application

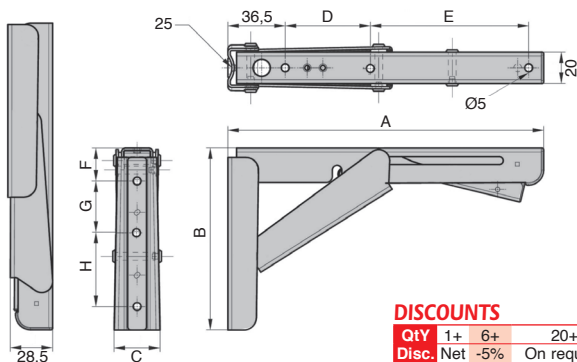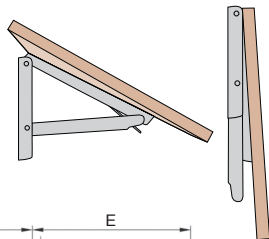

DISCOUNTS

Qty	1+	6+	20+
Disc.	Net	-5%	On request

Part N°	A	B	C	D	E	H	F	G	Admissible load (kg)	Weight (g)	Stock*	Price each 1 à 5
CPAS305-165H	307	165	29	98	156	67	38	45	150	515	✓	153,92 €
CPAS200-116H	201	116	29	155	-	-	21	80	175	332	✓	120,17 €

*Depending on availability - Dimensions in mm

Altri prodotti...



SRG

Chiusura a leva regolabile, Corsa da 117,4mm a 128mm



RPP

Piastra di giunzione per cinghia RPP, RPP5



HRV

Sistema di guida su binario a V Simple Select®, Binario con carrello




SH3

Ingranaggio elicoidale ad assi paralleli, Plastica lavorata (delrin)



OP2

Indicatore di posizione digitale (N. di giri), 3 cifre

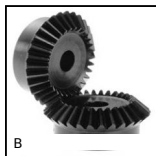

B

Ingranaggio conico - Acciaio 60C40, 1:1



WJRM

Pattino ibrido Drylin® W, Cuscinetto ibrido



GPB

Maniglia a tirante, Maschiatura modellata



CHTRB

Riduttore a rinvio angolare a L o a T,



M0

Coppia ruota e vite senza fine, Acciaio



CHTRP

Riduttore a rinvio angolare a L o a T,



BHC

Vite a testa bombata BHC, Inox A2

Prodotti correlati



CPAS

Asta snodata con fermo di sicurezza, Apertura verso l'altro