



Eye hook with latch **high resistance**

High strenght alloy steel

CRLHR

- Rigging equipment
- Material:
High strenght alloy steel red painted

Stamping


- ØM, CE, WLL, manufacturer

Info

- The Breaking load is calculated by multiplying the WLL by a safety factor of 4"

High strenght

Heavy loads

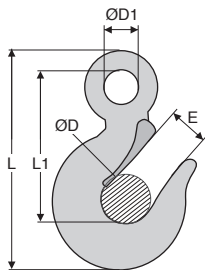

DISCOUNTS

Qty	1+	6+	20+	30+
Disc.	List	-10%	-20%	On request

Part number	WLL (kg)	ØD1	ØD	L	L1	E	Weight (kg)	Stock*	Price each 1 to 5
CRL19-1000/HR	1000	19	26	111	79	18	0,300		
CRL22-1500/HR	1500	22	31	125,7	90	22,5	0,422		
CRL27-2000/HR	2000	27	33,5	142	102	24	0,660		
CRL31-3000/HR	3000	31	40	162,5	118,5	29	0,780		
CRL39-5000/HR	5000	39	48	200	146	32	1,650		
CRL50-7000/HR	7000	50	59	257	171	40	3,130		
CRL61-11000/HR	11000	61	68,5	315	228	48	5,370		

*Dimensions in mm

Altri prodotti...



SSG1_304L
Ingranaggio dritto
Inox, Inox 304L



DOG258
Motoriduttore DC 12V
e 24V DC, da 12 a 15
Nm



T2
Cinghia di
posizionamento T,
T2.5 Poliuretano
armatura in acciaio



UGPC
Unità di guida per
cilindrico, Cuscinetto
corto



PS5
Riduttore a ruota e
vite senza fine, fino a
57 Nm



DOG111
Motoriduttore DC 12V
e 24V DC, da 1.5 a 6
Nm



M0
Vite senza fine,
Acciaio temprato




HTD14M_55
Puleggia dentata di
trasmissione tipo
HTD, HTD14 Ghisa



ZG0
Ingranaggio dritto in
plastica, Plastica



GALRUB
Rullo per
trasportatore, Caucciù

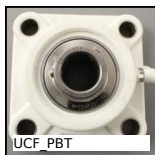

UCF PBT
Cuscinetto a flangia
quadrata polimero



CHAR5050_Z
Cerniera a molla,
avvitabile

Prodotti correlati



ADL
Anello di
sollevamento,
Maschio



ADL
Anello di
sollevamento,
Femmina



PPS
Anello di
sollevamento, Gancio
universale ad avvitare



VLBG
Anello di
sollevamento,
Girevole