



Eye hook with latch **high resistance**

High strenght alloy steel

CRLHR

- Rigging equipment
- Material:
High strenght alloy steel red painted

Stamping


- ØM, CE, WLL, manufacturer

Info

- The Breaking load is calculated by multiplying the WLL by a safety factor of 4"

High strenght

Heavy loads

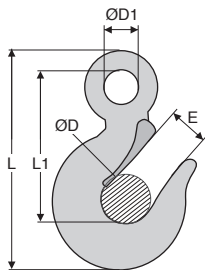

DISCOUNTS

Qty	1+	6+	20+	30+
Disc.	List	-10%	-20%	On request

Part number	WLL (kg)	ØD1	ØD	L	L1	E	Weight (kg)	Stock*	Price each 1 to 5
CRL19-1000/HR	1000	19	26	111	79	18	0,300		
CRL22-1500/HR	1500	22	31	125,7	90	22,5	0,422		
CRL27-2000/HR	2000	27	33,5	142	102	24	0,660		
CRL31-3000/HR	3000	31	40	162,5	118,5	29	0,780		
CRL39-5000/HR	5000	39	48	200	146	32	1,650		
CRL50-7000/HR	7000	50	59	257	171	40	3,130		
CRL61-11000/HR	11000	61	68,5	315	228	48	5,370		

*Dimensions in mm

Altri prodotti...



CHTRB

Riduttore a rinvio
angolare a L o a T,
fino a 16,5 Nm



SSG2_304L

Ingranaggio dritto
Inox, Inox 304L



H1

Ingranaggio elicoidale
ad assi incrociati a
90°, Acciaio 20NCD2



UFX

Giunto elastico
UNEFLEX, range




KGS

Vite a ricircolo di sfere
al metro, Vite a sfere
rullata, al metro



DOMI50

Kit di raccordo, Kit di
raccordo XZ

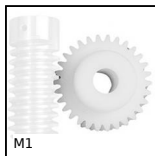

M1

Ruota per vite senza
fine, Plastica lavorata
(delrin)



VRSSss

Anello di
sollevamento,
Orientabile maschio
inox



DTR

Pignone tendicatena,
Ruota dentata in
acciaio



BLHB60

Rinvio angolare, fino a
70 Nm



LVT

Mini martinetto
motorizzato 1A, 1
ampere



RHTcsc

Ruota alte
temperature con foro
centrale, fino a 200kg

Prodotti correlati