


# Idler for plate chain



## DBL805

## For chain range 805

- For use with CAP805/SS plate chains
- Materials:
  - Low friction acetal
- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)
- For dimensions and bore tolerances,  
please refer to technical pages

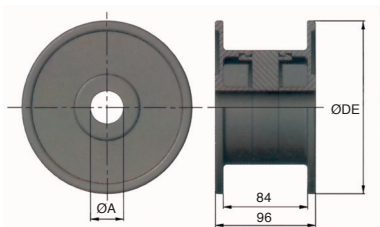

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request


Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL805-19-25	117	25	0,3	15,69 €
DBL805-19-30	117	30	0,3	15,69 €
DBL805-19-35	117	35	0,3	15,69 €
DBL805-19-40	117	40	0,3	15,69 €
DBL805-21-25	129	25	0,3	16,14 €
DBL805-21-30	129	30	0,3	16,14 €
DBL805-21-35	129	35	0,3	16,14 €
DBL805-21-40	129	40	0,3	16,14 €
DBL805-23-25	141	25	0,3	17,36 €
DBL805-23-30	141	30	0,3	17,36 €
DBL805-23-35	141	35	0,3	17,36 €
DBL805-23-40	141	40	0,3	17,36 €
DBL805-25-25	153	25	0,4	18,07 €
DBL805-25-30	153	30	0,4	18,07 €
DBL805-25-35	153	35	0,4	18,07 €
DBL805-25-40	153	40	0,4	18,07 €

Dimensions in mm

## Altri prodotti...



PRF\_ART  
Cerniere e giunti,  
Standard

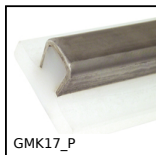

GMK17\_P  
Guida prodotto  
laterale piatta, Per  
imbottigliamento e  
imbollaggio



BLH70  
Rinvio angolare a L,  
da 26 a 128 Nm



SER69K-CLE  
Chiusura 1/4 di giro  
per agroalimentare,  
Chiave



DOMI\_MD  
Tavola rotante di  
regolazione Domino,  
40/1



ESCON  
Variatore di velocità  
5A, 5 A



PM2  
Coppia ruota e vite  
senza fine, Bronzo



GAC  
Chiusura a leva con  
serratura, Riscontro  
grezzo



RFVfp  
Riduttore inox a ruota  
e vite senza fine,  
Piede di supporto



YG1  
Ingranaggio dritto  
PRESTAZIONE, Acciaio  
35NCD6



SVT20  
Martinetto a vite - Vite  
traslante, Vite  
traslante



MHXred  
Manicotto di  
riduzione, Esagonale -  
inox

## Prodotti correlati



CAP805  
Catena a tapparella  
dritta, Larga serie 805



PR821  
Ruota di rinvio, Serie  
821 e 805