

# Idler for plate chain



## DBL805

## For chain range 805


- For use with CAP805/SS plate chains

- Materials:

Low friction acetal

- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)

- For dimensions and bore tolerances,  
please refer to technical pages

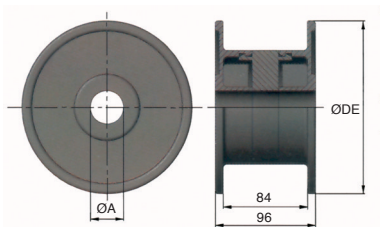

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL805-19-25	117	25	0,3	15,69 €
DBL805-19-30	117	30	0,3	15,69 €
DBL805-19-35	117	35	0,3	15,69 €
DBL805-19-40	117	40	0,3	15,69 €
DBL805-21-25	129	25	0,3	16,14 €
DBL805-21-30	129	30	0,3	16,14 €
DBL805-21-35	129	35	0,3	16,14 €
DBL805-21-40	129	40	0,3	16,14 €
DBL805-23-25	141	25	0,3	17,36 €
DBL805-23-30	141	30	0,3	17,36 €
DBL805-23-35	141	35	0,3	17,36 €
DBL805-23-40	141	40	0,3	17,36 €
DBL805-25-25	153	25	0,4	18,07 €
DBL805-25-30	153	30	0,4	18,07 €
DBL805-25-35	153	35	0,4	18,07 €
DBL805-25-40	153	40	0,4	18,07 €

Dimensions in mm

## Altri prodotti...



NKX  
Cuscinetto combinato  
senza anello interno,  
Needle and roller  
bearings



T2  
Cinghia di  
posizionamento T,  
T2.5 Poliuretano  
armatura in acciaio



PLM-C  
Magnete piatto di  
fermo, Magnete di  
fermo piatto



PFL  
P-FLEX, Vite a  
pressione



PW\_PWG05  
Ruota di precisione,  
Bronzo



SHA  
Volantin pieno,  
Poliammide



AT10-BAR  
Barra dentata, AT10



MBF  
Manicotto filettato di  
bloccaggio, Montaggio  
e regolazione rapidi



ZBconique  
Ingranaggio conico in  
plastica, 1:1



HTD8M\_20  
Puleggia dentata di  
trasmissione tipo  
HTD, HTD8 Ghisa



ARTE  
Silent block, Carico  
multidirezionale



PAT123  
Piede snodato con  
base lamiera Ø123, Ø  
123

## Prodotti correlati



CAP805  
Catena a tapparella  
dritta, Larga serie 805



PR821  
Ruota di rinvio, Serie  
821 e 805