

# Idler for plate chain



## DBL805

## For chain range 805


- For use with CAP805/SS plate chains

- Materials:

Low friction acetal

- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)

- For dimensions and bore tolerances,  
please refer to technical pages

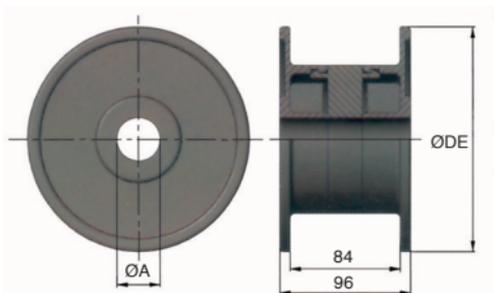

### DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL805-19-25	117	25	0,3	15,69 €
DBL805-19-30	117	30	0,3	15,69 €
DBL805-19-35	117	35	0,3	15,69 €
DBL805-19-40	117	40	0,3	15,69 €
DBL805-21-25	129	25	0,3	16,14 €
DBL805-21-30	129	30	0,3	16,14 €
DBL805-21-35	129	35	0,3	16,14 €
DBL805-21-40	129	40	0,3	16,14 €
DBL805-23-25	141	25	0,3	17,36 €
DBL805-23-30	141	30	0,3	17,36 €
DBL805-23-35	141	35	0,3	17,36 €
DBL805-23-40	141	40	0,3	17,36 €
DBL805-25-25	153	25	0,4	18,07 €
DBL805-25-30	153	30	0,4	18,07 €
DBL805-25-35	153	35	0,4	18,07 €
DBL805-25-40	153	40	0,4	18,07 €

Dimensions in mm

## Altri prodotti...



Q6

Cuscinetto radiale a sfere, Acciaio



CHTRP

Riduttore a rinvio angolare a L o a T, fino a 87,3Nm



RPB

Vite a ricircolo di sfere, Supporto



VML

Volantino a lobi, Vite di pressione



OP3\_14\_06

Accessorio per indicatori, Boccola di riduzione



PTGR

Puleggia folle, Per cinghia tonda



PRES4HR

Pressa manuale da banco, Pressione fino a 600kg



NT63

Riduttore coassiale a treni paralleli, da 8 to 20 Nm - a treni paral...



AC

Piastrina di riscontro, 15mm



UTKswc

Guida lineare Utilitrack®, Ruota di



RTK

Giunto Bowex®, a dentatura bombata,



PRF\_RR

Elementi di giunzione, Piastra di raccordo

## Prodotti correlati



CAP805

Catena a tapparella dritta, Larga serie 805



PR821

Ruota di rinvio, Serie 821 e 805