

Idler for plate chain



DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:



Low friction acetal
Stainless steel screws

- Operating temp.: -40°C to +85°C
(+70°C in humid environments)

- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

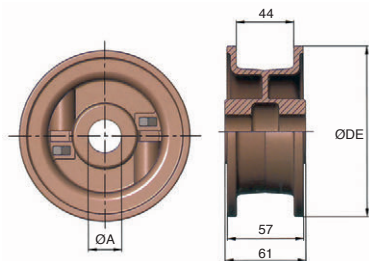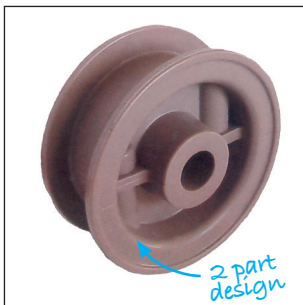

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL820-21-25	129	25	0,3	11,71 €
DBL820-21-30	129	30	0,3	11,71 €
DBL820-21-35	129	35	0,3	11,71 €
DBL820-21-40	129	40	0,3	11,71 €
DBL820-23-25	141	25	0,4	13,14 €
DBL820-23-30	141	30	0,4	13,14 €
DBL820-23-35	141	35	0,4	13,14 €
DBL820-23-40	141	40	0,4	13,53 €
DBL820-25-25	153	45	0,4	13,39 €
DBL820-25-30	153	30	0,4	13,39 €
DBL820-25-35	153	35	0,4	13,39 €
DBL820-25-40	153	40	0,4	13,39 €

Dimensions in mm

Altri prodotti...




QN

Cuscinetto a singola corona di rulli cilindrici, Anello esterno libero



GFx

Giunto a dentatura bombata serie economica, Acciaio e poliammide

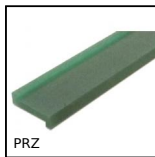

PRZ

Profilo supporto per catena, Profilo a Z ad incastro



RVM25

Riduttore manuale, Rinvio angolare



OPFL_OPPM

Accessorio per indicatori, Pomello di manovra



ACL-PR

Elementi di giunzione, Collegamento a 90°



FDSQ

Flexible drive shaft, Masterflex® Steel, with PVC casing



DOMI_MD

Tavola rotante di regolazione Domino, 55/1



BAN

Connettore / supporto per profili alluminio,



F7-P-AM

Visualizzatore multifunzione, Banda



ESCON

Variatore di velocità 5A, 5 A



RTE

Rotex®, elastico, ghisa

Prodotti correlati



CAP820

Catena a tapparella dritta, Stretta serie 820



CAP815

Catena a tapparella dritta, Stretta serie 815



PT820

Pignone di trazione, Serie 820 e 815



PR820

Ruota di rinvio, Serie 820 e 815