

Idler for plate chain



DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:

Low friction acetal
Stainless steel screws



- Operating temp.: -40°C to +85°C

(+70°C in humid environments)

- For dimensions and bore tolerances,
please refer to technical pages

Advantage

- Two part design facilitates easy assembly

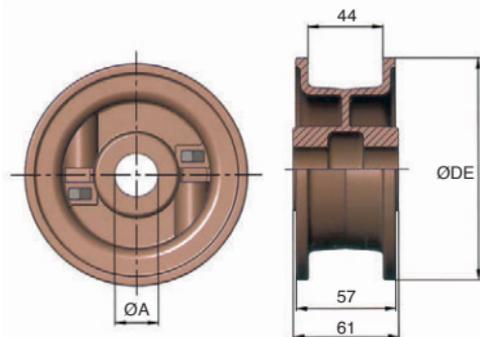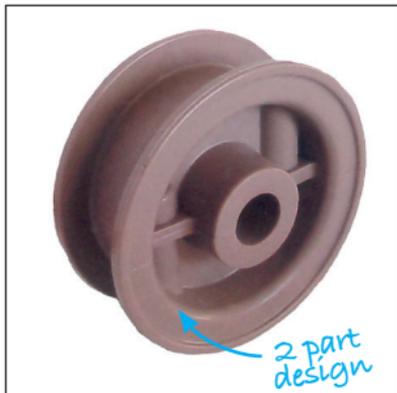

DISCOUNTS

Qty.	1+	5+	10+
Disc.	List	-5%	On request

Part number	ØDE	Bore ØA	Weight (kg)	Price each 1 to 4
DBL820-21-25	129	25	0,3	11,71 €
DBL820-21-30	129	30	0,3	11,71 €
DBL820-21-35	129	35	0,3	11,71 €
DBL820-21-40	129	40	0,3	11,71 €
DBL820-23-25	141	25	0,4	13,14 €
DBL820-23-30	141	30	0,4	13,14 €
DBL820-23-35	141	35	0,4	13,14 €
DBL820-23-40	141	40	0,4	13,53 €
DBL820-25-25	153	45	0,4	13,39 €
DBL820-25-30	153	30	0,4	13,39 €
DBL820-25-35	153	35	0,4	13,39 €
DBL820-25-40	153	40	0,4	13,39 €

Dimensions in mm

Altri prodotti...




PM3

Vite senza fine,
Acciaio temprato



MFBC

Giunto a soffietto,
Alluminio e bronzo -
con ganascia di
serraggio

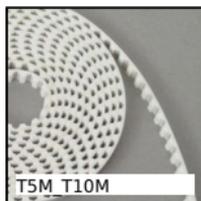

T5M T10M

Cinghia aperta al
metro tipo T, T10
Poliuretano armatura
in acciaio



BABA

Perno autobloccante,
Acciaio



RIMple

Ruota di livellamento,
Con piastra



PSG08HC

Ingran. dritto di
precisione trattato
skiving, Acciaio
20NCD2 cement...



M0

Ruote per viti senza
fine, Bronzo



BAGSS

Anello di bloccaggio
inox, Inox



BCAss

Boccola scanalata
Inox, Inox



CHAB

Hinge with stop,
Hinge



EKN

Giunto a soffietto
Gerwah®, da 0.5 a



CHB

Single output shaft,
For CHB gearbox

Prodotti correlati



CAP820

Catena a tapparella
dritta, Stretta serie
820



CAP815

Catena a tapparella
dritta, Stretta serie
815



PT820

Pignone di trazione,
Serie 820 e 815



PR820

Ruota di rinvio, Serie
820 e 815